


KEMET Part Number: EFF4(05)-80X80T0800
(UFSEF4050FT080, EFF4(05)80X80T0800)

KEMET, EFF4, Flex Suppressors, Noise Suppression

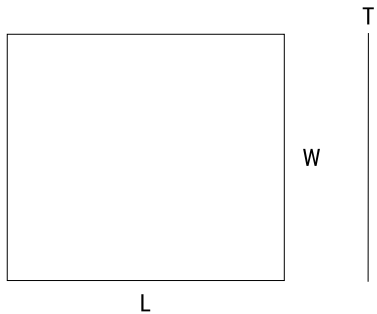

General Information	
Series:	EFF4
Style:	Sheet
Description:	Flex Suppressor Flame Retardant Type
Features:	Flame Retardant Type
RoHS:	Yes
Qualifications:	UL94 V-0, UL File No.E176124, AEC-Q200
Environment:	RoHS Compliant, Halogen Free, PVC Free, Lead Free, Red Phosphorus Free

Dimensions	
Sheet Size	80x80mm
L	80mm NOM
W	80mm NOM
T	0.5mm NOM

Specifications	
Temperature Range:	-40/+125°C
Magnetic Permeability:	140 μ At 3MHz
Effective Frequency:	10 GHz MAX
Resistance:	1 MOhms MIN
Specific Gravity:	3.7 Atm TYP

Packaging Specifications	
Weight:	12.1 g