

# SEALING PLUG 20X22 RD - Sealing plug



1421862

<https://www.phoenixcontact.com/in/products/1421862>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Sealing plug, color: red

## Commercial data

|                                      |                     |
|--------------------------------------|---------------------|
| Item number                          | 1421862             |
| Packing unit                         | 10 pc               |
| Minimum order quantity               | 10 pc               |
| Sales key                            | BF7                 |
| Product key                          | AF7DZX              |
| Catalog page                         | Page 707 (C-2-2019) |
| GTIN                                 | 4055626287621       |
| Weight per piece (including packing) | 4.338 g             |
| Weight per piece (excluding packing) | 3.931 g             |
| Customs tariff number                | 39235090            |
| Country of origin                    | DE                  |

# SEALING PLUG 20X22 RD - Sealing plug



1421862


<https://www.phoenixcontact.com/in/products/1421862>

## Technical data

### Product properties

|              |               |
|--------------|---------------|
| Product type | Sealing plugs |
|--------------|---------------|

### Dimensions
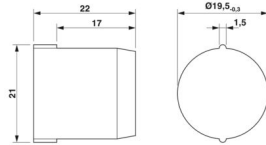
|                     |                                                                                    |
|---------------------|------------------------------------------------------------------------------------|
| Dimensional drawing |  |
| Length              | 22 mm                                                                              |
| Diameter            | 19.5 mm                                                                            |

### Material specifications

|          |    |
|----------|----|
| Material | PA |
|----------|----|

### Cable/line

|              |     |
|--------------|-----|
| Halogen-free | yes |
|--------------|-----|

### Environmental and real-life conditions

#### Ambient conditions

|                                 |                   |
|---------------------------------|-------------------|
| Ambient temperature (operation) | -60 °C ... 100 °C |
|---------------------------------|-------------------|

### Mounting

|               |                                                                                                                         |
|---------------|-------------------------------------------------------------------------------------------------------------------------|
| Assembly note | The head of the sealing plug must still be visible after mounting in the screw connection (see "after mounting" photo). |
|---------------|-------------------------------------------------------------------------------------------------------------------------|

# SEALING PLUG 20X22 RD - Sealing plug


1421862

<https://www.phoenixcontact.com/in/products/1421862>



## Drawings

Dimensional drawing

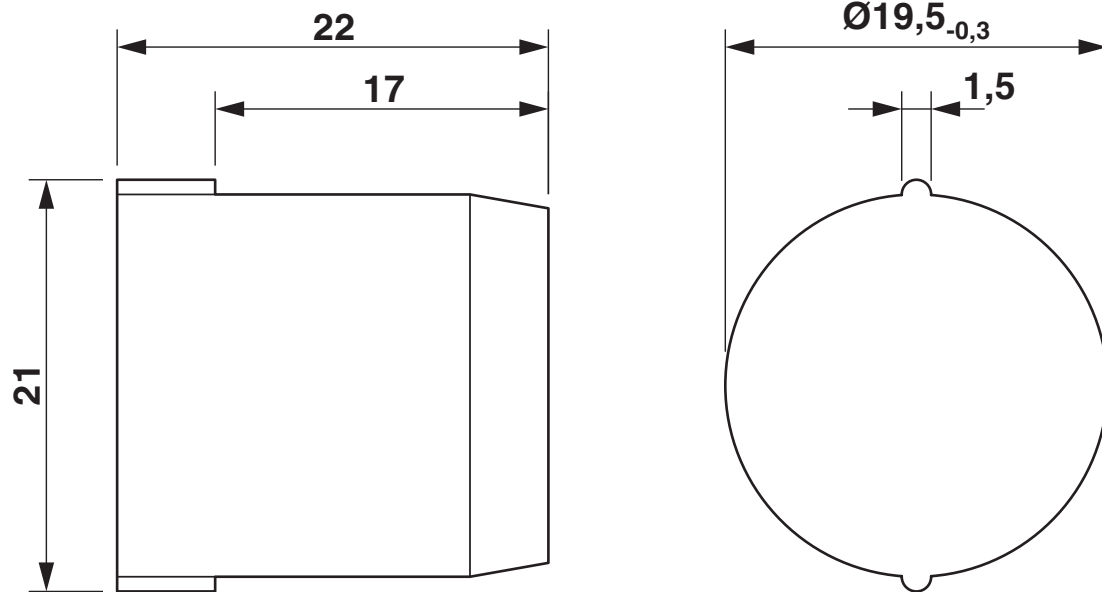

Dimensional drawing

# SEALING PLUG 20X22 RD - Sealing plug



1421862

<https://www.phoenixcontact.com/in/products/1421862>

## Classifications

### ECLASS

|             |          |
|-------------|----------|
| ECLASS-11.0 | 27144433 |
| ECLASS-13.0 | 23111190 |

### ETIM

|          |          |
|----------|----------|
| ETIM 9.0 | EC000032 |
|----------|----------|

### UNSPSC

|             |          |
|-------------|----------|
| UNSPSC 21.0 | 39121300 |
|-------------|----------|

# SEALING PLUG 20X22 RD - Sealing plug



1421862

<https://www.phoenixcontact.com/in/products/1421862>

## Environmental product compliance

### EU RoHS

|                                         |                    |
|-----------------------------------------|--------------------|
| Fulfills EU RoHS substance requirements | Yes, No exemptions |
|-----------------------------------------|--------------------|

### China RoHS

|                                        |                                          |
|----------------------------------------|------------------------------------------|
| Environment friendly use period (EFUP) | EFUP-E                                   |
|                                        | No hazardous substances above the limits |

### EU REACH SVHC

|                                     |                            |
|-------------------------------------|----------------------------|
| REACH candidate substance (CAS No.) | No substance above 0.1 wt% |
|-------------------------------------|----------------------------|

Phoenix Contact 2025 © - all rights reserved  
<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.  
A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420  
[info@phoenixcontact.co.in](mailto:info@phoenixcontact.co.in)