


# MP22DLRINRG024S5 Datasheet

Product Name // MP22DLRINRG024S5 Ring Illumination  
Vandal Resistant Switch

 [View Product Page](#)

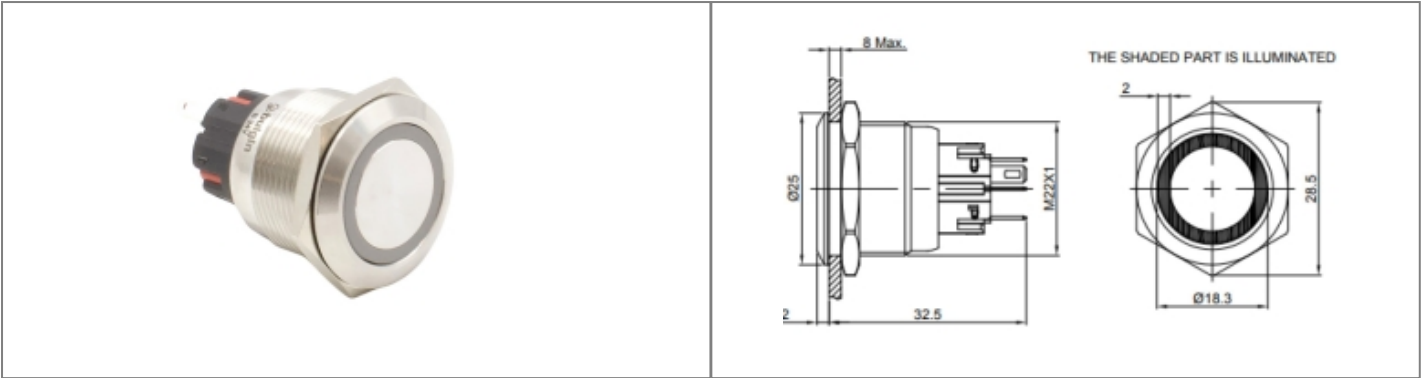

## // Product Description:

- |                                                                                                       |                                                                                                     |
|-------------------------------------------------------------------------------------------------------|-----------------------------------------------------------------------------------------------------|
|  MP22 Range          |  Green             |
|  DPDT               |  24V              |
|  Latching          |  Stainless Steel |
|  Ring Illumination |  IP65            |

## // General Information:

|                                  |                                           |
|----------------------------------|-------------------------------------------|
| Product Display Title:           | Ring Illumination Vandal Resistant Switch |
| Product Family:                  | Switch Range                              |
| Product Series:                  | Vandal Resistant Switches                 |
| Bezel Finish:                    | Machined                                  |
| Body Colour:                     | Stainless Steel                           |
| Body Material:                   | Stainless Steel                           |
| Body Material Type:              | Metal                                     |
| Current Rating:                  | 5A 250V                                   |
| Diameter:                        | 22mm                                      |
| Dielectric Withstanding Voltage: | 1500V                                     |
| Durability:                      | 50,000                                    |
| Function:                        | Push Button Switch                        |
| Illumination Colour:             | Green                                     |
| Illumination Shape:              | Ring                                      |
| Illumination Voltage:            | 24V                                       |
| Ip Rating:                       | IP65                                      |
| Lamp Type:                       | LED                                       |
| Material Finish:                 | Machined                                  |
| Max Operating Temperature:       | 55°C                                      |
| Min Operating Temperature:       | -25°C                                     |
| Max Panel Thickness:             | 8mm                                       |
| Operating Humidity:              | 45~85 RH(Non condensing)                  |
| Panel Cut Out:                   | 22mm Diameter circle                      |
| Rohs Compliant:                  | Yes                                       |
| Switch Body Colour:              | Stainless Steel                           |
| Switch Body Material:            | Stainless Steel                           |
| Switch Button Colour:            | Stainless Steel                           |
| Switch Button Material:          | Stainless Steel                           |
| Switch Circuit:                  | DPDT                                      |
| Switch Series:                   | MP22                                      |
| Switch Shape:                    | Round                                     |
| Switch Type:                     | Pushbutton                                |
| Switching Type:                  | Latching                                  |
| Thread Size:                     | M22                                       |

### // Product PDF Links

 [22mm Vandal Resistant Switch](#)

### // Product 3D CAD Model Links

 [MP22DLRINRG024S53D CAD Model](#)



Have a question or project enquiry  
you'd like to talk to us about?



[Click Here To Contact Us](#)