



Brand of NTN corporation


Technical data

BBET12UU

Super ball bushings



VISUAL (S)

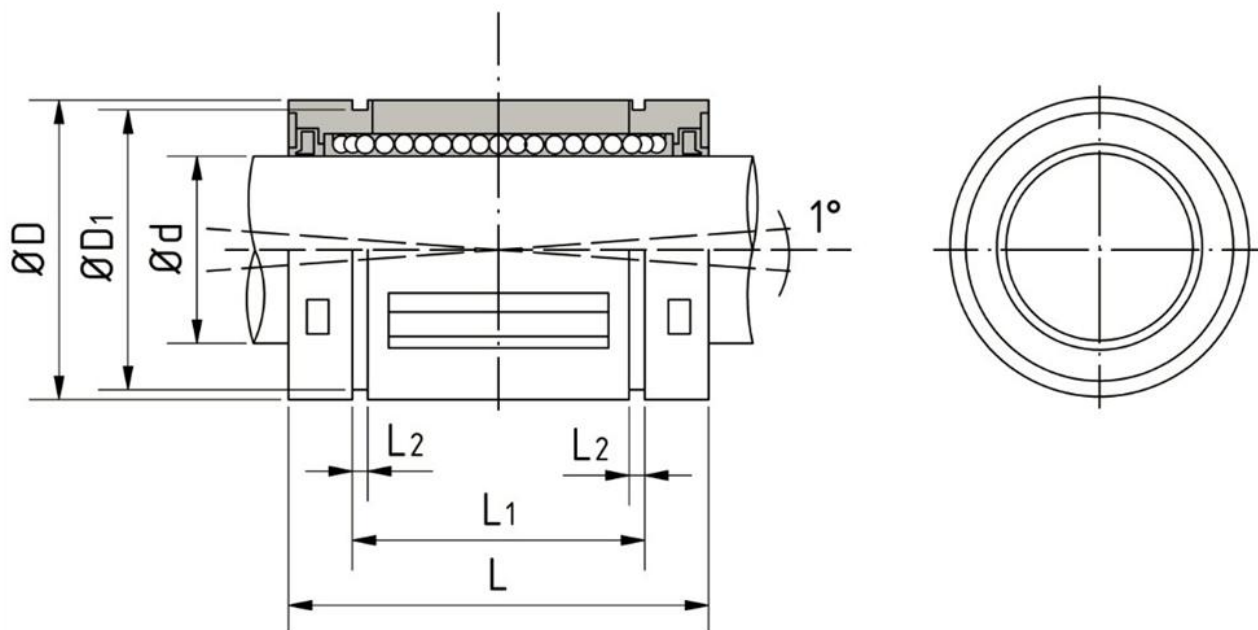

PRODUCT DEFINITION

Brand	SNR
Design type	BBET
Ball bushings category	Super ball bushings, closed
Standard	ISO dimension
Number of seals	2
Material outer cylinder or steel segments	100Cr6
Material Cage	PA
Initial greasing	Non/No
Re-lubricable	Oui/Yes



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

d - Internal diameter	12 mm
d - Internal diameter tolerance	0,008/0
D - External diameter	22 mm
L - Length	32 mm
L - Length tolerance	0,2/-0,2
L1	22,9 mm
L1 tolerance	0/-0,2
D1 - Diameter	21 mm
L2	1,3 mm
Diameter F H11	3 mm
J	0,7 mm
Number of ball rows	5
Mass	0,021 kg

PRODUCT PERFORMANCE

Cmin	1,02 kN
Cmax	1,492 kN
C0min	1,29 kN
C0max	1,887 kN
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	80 °C

ESHOPDONOTDISPLAY

Reference	BBET12UU
Image	BBET_1.JPG, BBET_3.JPG



ESHOPDONOTDISPLAY	
Send to Eshop	Yes
Send to Paper Catalog	Yes
Tracepart	Oui/Yes

