



Datasheet

Stock No: 835-4112

ENGLISH

RS Pro M20 Brass Cable Gland with Locknut

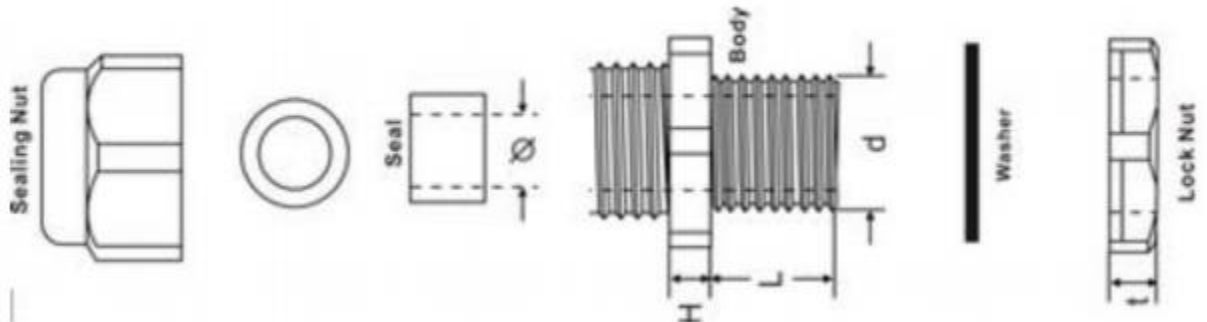


Features:

EMC Brass Cable Gland that is designed for use with unarmoured, elasto and plastic or braided cables. The gland can be used to establish a continuous electrical path from the shield of the cable to the equipment ground, creating a secure shield connection. It's easy to install and allows the cable to be centralised, provides strain relief and seals from moisture and dust in accordance to IP68. Supplied with Locknut

Specifications:

Material:	Brass Nickel Plated
Sealing:	Nitrile Butadiene Rubber
Temperature:	-40°C to +110°C, Short time +120°C
Standards:	RoHS, CE, IP68

Dimensions:


RS Article	SIZE	Cable Range(Φ) (MM)	d (MM)	L (MM)	H (MM)	PCS/PACK
8354119	M16×1.5	4—8	16	6	18	1
8354112	M20×1.5	6—12	20	7	22	1
8354116	M25×1.5	10—16	25	9	27	1
8354125	M32×1.5	15—22	32	9	35	1
8354128	M40×1.5	21—30	40	11	45	1
8354122	M50×1.5	30—38	50	11	57	1
8354087	PG9	4—8	15.2	6	17	1
8354096	PG11	5—10	18.6	6	20	1
8354099	PG13.5	6—12	20.4	7	22	1
8354093	PG16	8—14	22.5	10	24	1
8354103	PG21	13—18	28.3	8	30	1
8354106	PG29	18—25	37	11	40	1
8354100	PG36	22—32	47	9	50	1

Brass Locknut:

RS CODE	SIZE (AG)	Spanner Size (MM)	Thickness (t)
8354119	M16×1.5	18	2.2
8354112	M20×1.5	22	3
8354116	M25×1.5	27	3
8354125	M32×1.5	35	3.5
8354128	M40×1.5	50	4.5
8354122	M50×1.5	57	5
8354087	PG9	18	2.5
8354096	PG11	21	3
8354099	PG13.5	23	3
8354093	PG16	27	3
8354103	PG21	30	3.5
8354106	PG29	40	4
8354100	PG36	50	4.5

