


KRV26-X-B

Yoke type track roller

Stud type track rollers KRV...-PP, with axial guidance, full complement needle roller set, plastic axial plain washers on both sides

Schaeffler ID:
0075991100000

Technical information

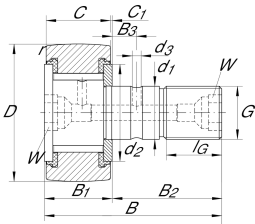

Your current product variant

Sealing	SPSP	Gap seal on both sides
Outer Ring profile	X	Cylindrical profile
Grease nipples	2x	Drive-fit lubrication nipple unmounted 2x
Relubrication feature	KS	Via head and stud
Assembling aid head	I6	Hexagon socket
Mounting aid stud	I6	Hexagon socket

Main Dimensions & Performance Data

D	26 mm	Outside diameter
d 1	10 mm	Fit diameter of roller stud / stud
B	36 mm	Width
C r w	7.300 N	Basic dynamic load rating, radial
C 0r w	11.600 N	Basic static load rating, radial
C ur w	1.520 N	Fatigue load limit, radial
n D G	2.600 1/min	Speed on permanent grease lubrication
≈m	58,117 g	Weight



Dimensions

B 1	13,2 mm	Width of thrust washer
B 2	23 mm	Bolt/stud length effectively
C	12 mm	Width, outer ring
C 1	0,6 mm	Protrusion outer ring to thrust washer
r min	0,3 mm	Minimum chamfer dimension
d 2	17,5 mm	Stop diameter of thrust washer
G	M10X1	Thread
l G	12 mm	Thread length
W	5 mm	Width of flats

Additional information

	NIPA1X4,5	Drive-fit lubrication nipple
M A	15 Nm	Tightening torque nut