


PXP6040/AA/5M00 Datasheet

 [View Product Page](#)

Product Name // Plastic Body Overmoulded USB Cable
Standard 2.0 A Plug to Sealed 2.0 A Plug 5M Cable

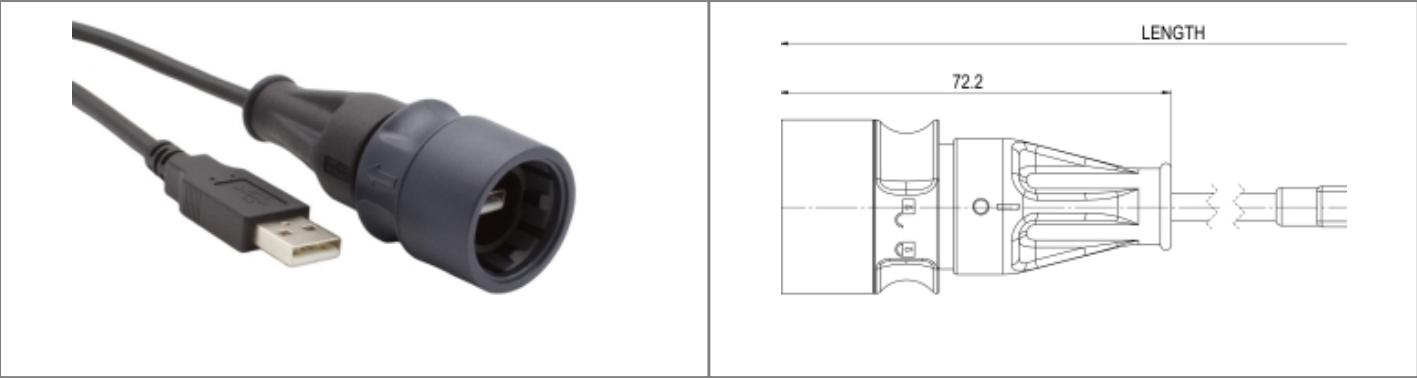

// Product Description:

- Pre-Wired Plastic Body Overmoulded USB 2.0 Cable
- Water and dustproof to IP68 & IP69K when mated with compatible connector
- 30 degree push twist locking, tamperproof lock prevents accidental un-mating
- Choice of USB A, B & C connections
- Choice of cable lengths
- PXP6081 Sealing Cap available separately to maintain IP rating of unmated connectors
- Mate with 6000 Series Plastic Body USB Panel Mount Connectors

// General Information:

Product Display Title:	Plastic Body Overmoulded USB Cable Standard 2.0 A Plug to Sealed 2.0 A Plug 5M Cable
Product Family:	Circular Data Connectors
Product Series:	6000 Series - USB Buccaneer
Approvals:	CSA, UL, VDE
Body Material:	Polycarbonate/Polybutylene Terephthalate (PC/PBT)
Body Material Type:	Plastic Body
Cable Length:	5m
Contact Type:	Plug Contact
Coupling Type:	Push-Twist
Current Max:	1A
Data Cable Type:	Standard 2.0 A Plug to Sealed 2.0 A Plug
Diameter Over Coupling Ring Mm:	32mm
Flamability Rating:	UL94V-0
Function:	Flex to Standard Connector Double Ended Cable
Ip Rating:	IP66, IP68, IP69K
Max Operating Temperature:	+70°C
Min Operating Temperature:	0°C
Number Of Contacts:	4 Contacts
Voltage Max:	30V

// Product PDF Links

 [6000 Series HDMI Product Data](#)

// Product 3D CAD Model Links

 [PXP6040/AA/5M003D CAD Model](#)