


QL-1060N

DK Labels



Versatile and Easy to use thermal label

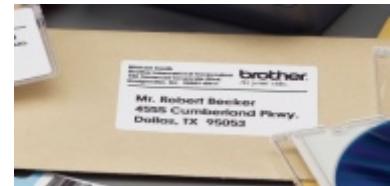

Copy

Catalogue Spec

- Save money, by sharing your labeller across your network
- Versatile – print labels up to 102mm wide for a variety of industrial applications, from letters and parcels to signage and name badges
- Professional – Produce industry-standard shipping labels with any common barcode protocol, to meet ANSI X3.182 specifications can be printed quickly and in larger production runs
- Time-saving – with up to 69 labels per minute print speed, you can complete the largest of production runs in no time
- Durable - Brother DK label rolls are made of high quality materials, to ensure the printed text and barcodes stay readable even after shipping.
- Money-saving – direct thermal print technology eliminates toner, ink and ribbon costs
- Easy to use - print address labels directly from Microsoft Word, Excel and Outlook
- No misaligned text – preview your labels on your PC first before you print

What's in the Box

- 62mm black on white continuous length tape
- Large shipping labels (40 labels)
- CD ROM
- Quick start guide
- USB Cable
- AC adapter
- DK roll guide

Hardware

QL-1060N for EU	
Dimensions	170mm(W) x 220mm(D) x 147.5mm(H) 6.7"(W) x 8.7"(D) x 5.8"(H)
Weight	1.73kg (without DK roll) 3.8pounds (without DK roll)
Housing Color	Black
Key Board	No
Number of Keys	3 (On/Off, Feed, Cut)
Cutter	Durable Auto cutter (User unreplaceable)
Auto Half Cutter	No
Power supply	Internal S/W Power Supply
LCD	No
LED	1 (3 color - Green, Red, Orange)
Print Method	Thermal
Attachments	CD-ROM (P-touch Editor 5.0 for Windows, P-touch Address Book 1.1, P-touch Editor 5.0 for Mac, Printer Driver, User's Guide, P-touch Template tools, ESC/P tools) Setup & Operation Guide DK Rolls Line-up Guide Label Tray USB cable Warranty card DK-11241 (102mm x 152mm White Paper Labels) Starter roll (40 labels) DK-22205 (62mm Continuous Length Paper Tape) Starter roll (8 m) AC Power cord EEE insertion
Roll Type	DK rolls (DK Die-cut Labels / DK Continuous Length Tape)
Roll Width	Max. Label width 102mm (4")
Print Head	300 dpi / 1296 dots
Print Speed	110 mm (4.3") / sec. 69 standard address labels / min.
Strap / Handle	No
Computer Interface	USB, RS-232C, 10/100 BASE-TX Wired Ethernet
LCD Mylar	No
Mylar Sticker	No

Software and Firmware

QL-1050 for EU	
Printer Driver	QL-1060N
Label Editing Software	Win: P-touch Editor ver. 5.0, P-touch Address Book ver. 1.1 Mac: P-touch Editor ver. 5.0
Maximum Print Width	98.6mm (3.9") max.

Printable Label Length	25.4mm (1") - 3m (10') (USB) 25.4mm (1") - 1m (3') (Serial)
Number of Printing	1 - 9999 (USB) 1 - 99 (Serial)
Bar Code	Software side: CODE39, CODE128, EAN8, EAN13, EAN128, UPC-A, UPC-E, I-2/5(ITF), CODABAR, ISBN-2, ISBN-5, Laser Bar Code, POSTNET, QR code, MicroQR code, PDF417, Data Matrix, MaxiCode, Micro PDF 417, RSS-14,RSS-Limited, RSS Expanded Machine side: CODE39, CODE128, EAN8, EAN13, EAN128, UPC-A, UPC-E, I-2/5(ITF), CODABAR, QR code, MicroQR code, PDF417, Data Matrix, MaxiCode, Micro PDF 417, RSS-14,RSS-Limited, RSS Expanded
Printer control command	Raster mode ESC/P mode P-touch Template mode
Template Transfer	YES
Memory for transferred data	99 Templates or 2048KB
Character code set	Standard character code Windows-1252 Western Europe character code Windows-1250 Eastern Europe character code
Built in Fonts	Bitmap fonts: Helsinki, Brussels, Letter Gothic Bold, San Diego, Brougham Outline fonts: Helsinki, Brussels, Letter Gothic
Built in Font size	Bitmap fonts: 24 dots, 32 dots, 48 dots Outline fonts: 33 dots - 400 dots (22 sizes)
Built in Font style	Outline, Shadow, Outline+Shadow, Italic, Underline, Bold, Vertical
Built in Font widths (ESC/P printing only)	x2 (Width), x2 (Height), x1/2 (Width)
Add-in for Microsoft	Word, Outlook, Excel
Database file compatibility	csv, txt, mdb, xls
Special printing	Mirror printing Vertical printing Rotated Printing
Time & Date Stamp	PC Generated
Number of Preset Templates	No
Nmber of Date formats	No
Nmber of Time formats	No
Number of Preset messages	No