




CM-TD RX7s 150W 942 NDL

Article number: 146469

BAI CM-TD RX7s 95V 150W 4000K 13500lm 23x137mm V±45° CRI90-100 12.000u Ceramic Metal Halide
CMH-TD CDM-TD HQI-TS CMI-TD HRI-TS RCC-TS Compact halogen metal halide lamp

The Ceramic Metal Halide (CMH/CDM) lamps from Bailey Lights continue to offer possibilities for lighting design where a LED can't be used yet. These lamps provide excellent overall light quality, excellent lumen maintenance, efficiency while maintaining long life and reliability. The lamp base is ceramic. These lamps are often used in shops, shop windows and museums.

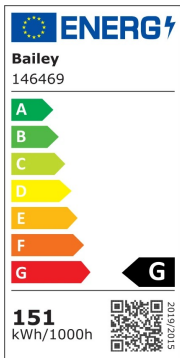

General ETIM properties

ETIM group	Lamps
ETIM class	Halogen metal halide lamp without reflector
Name	CM-TD RX7s 150W 942 NDL
Brand	Bailey
Productseries	HID
Producttype	CM-TD RX7s

ETIM specifications

Socket	RX7s
Lamp power [W]	150
Colour temperature [K]	4000
Luminous flux [lm]	13500
Lamp voltage [V]	85 - 85
UV protection	Yes
Colour rendering index CRI	90-100
Colour of light according to EN 12464-1	Neutral white 3300-5300 K
Lamp efficacy [lm/W]	90
Lamp shape	Tube, double-ended
Material discharge tube	Ceramics
Burning position	h45
Diameter [mm]	23
Total length [mm]	137
External ignitor required	Yes
External ballast required	Yes
Closed luminaire required	Yes
Sun tanning lamp	No
Colour	Colourless
Colour of light	942
Model	Clear
Lamp designation	TD
Weighted energy consumption in 1000 hours [kWh]	151
Average nominal lifetime [h]	12000
Energy efficiency class according to EU regulation 2019/2015	F

Complementary articles



92200236499
POWERTRONIC INTELLIGENT
PTI | 150/220...240 l