



1578

TOOL TROLLEY with 6 drawers

Body:

- Dimensions: H 930 x W 605 x D 375 mm
- Working platform in ABS, with 3 compartments for small parts
- With handle for easy pushing, pulling and turning
- Heel protection for your safety
- Sheet steel, corrosion resistant and scratch-proof powder-coated, GEDORIT blue

Drawers:

- Central locking with cylinder lock
- 4 wide drawers (W 480 x D 325 x H 75 mm)
- 1 wide drawer (W 480 x D 325 x H 120 mm)
- 1 wide drawer (W 480 x D 325 x H 210 mm)
- All drawers open either side
- Can be individually equipped with length and crosswise dividers (can be ordered individually)

- Load capacity per drawer 20 kg

- Sheet steel, corrosion resistant and scratch-proof powder-coated, GEDORIT silver

GEDORE Chassis

- Total load capacity 200 kg
- 2 high-performance wheels on roller bearings (fixed castors Ø 140 mm)
- 2 smooth running wheels on ball bearings (swivel castors Ø 100 mm), one with total brake
- The GEDORE trapezoidal axle construction secures smooth running, manoeuvrability and track-keeping also in case of maximum loads

Accessories:

- 6 length- (LT) and 2 crosswise (QT) dividers from zinc-plated sheet steel

Options:

- Can be equipped with GEDORE tool modules (1500 ES/1500 CT)
- Special colours and designs available on request
- Delivery without tools and accessories



H	W	D	LD	CD	kg	Code	No.
930	605	375	6x	2x	43.5	9018140	1578

Optional accessories

TOP TOOL CHESTS

1430

TOOL CHEST

- Designed particularly as top box for trolleys 1580, 1585, 2000, 2500, 3010

Body:

- Dimensions: H 305 x W 625 x D 400 mm
- ABS top
- Heel and impact protection for your safety
- Sheet steel, corrosion resistant and scratch-proof powder-coated, GEDORIT blue

Drawers:

- Central locking with cylinder lock
- 3 wide drawers (W 480 x D 325 mm) fully extendable, removable
- Each drawer with safety locking, single-hand operation
- Ball-bearing guide rails
- Can be individually equipped with length and crosswise dividers (can be ordered individually)
- Load capacity per drawer 40 kg
- Sheet steel, corrosion resistant and scratch-proof powder-coated, GEDORIT silver


- Sheet steel, corrosion resistant and scratch-proof powder-coated, GEDORIT silver

Accessories:

- 6 length- and 2 crosswise dividers in zinc-plated sheet steel

Options:

- Can be equipped with GEDORE tool modules (1500 ES/1500 CT)
- Special colours and designs available on request
- Delivery without tools and accessories

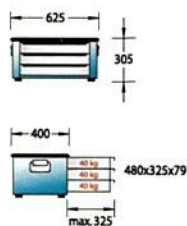

1431

TOOL CHEST

- Designed particularly as top box for trolleys 1580, 1585, 2000, 2500, 3010

Body:

- Dimensions: H 305 x W 625 x D 400 mm
- ABS top
- Heel and impact protection for your safety
- Sheet steel, corrosion resistant and scratch-proof powder-coated, GEDORIT blue

Drawers:

- Central locking with cylinder lock
- 2 wide drawers (W 480 x D 325 mm) fully extendable, removable
- Each drawer with safety locking, single-hand operation
- Ball-bearing guide rails
- Can be individually equipped with length and crosswise dividers (can be ordered individually)
- Load capacity per drawer 40 kg
- Sheet steel, corrosion resistant and scratch-proof powder-coated, GEDORIT silver


- Sheet steel, corrosion resistant and scratch-proof powder-coated, GEDORIT silver

Accessories:

- 6 length- and 2 crosswise dividers in zinc-plated sheet steel

Options:

- Can be equipped with GEDORE tool modules (1500 ES/1500 CT)
- Special colours and designs available on request
- Delivery without tools and accessories

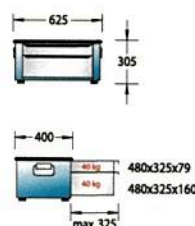

H	W	D	LD	CD	kg	Code	No.
305	625	400	3x	2x	40	9018140	1430

H	W	D	LD	CD	kg	Code	No.
305	625	400	2x	2x	40	9018140	1431