

FEATURES

- Various cable lengths
- 2, 4, 6 and 8 socket versions are all available
- Extension for both domestic and industrial purposes
- UK Plug and sockets

RS PRO 1m 4 Socket Type G - British Extension Lead, 250 V

RS Stock No.: 849-6159



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

Brought to you by RS Pro, these convenient and efficient extension sockets are suitable for use in both the home and workplace. With both multiple socket versions available and a 2 m up to 10 m lead, the applications from each extension lead can range from powering TV's and phone chargers. All the way up to powering multiple industrial machines or appliances. All models are highly reliable and excellent quality.

General Specifications

Type	Socket Strip
Colour	White
Number of Sockets	4
Surge Protection	No
Switchable	No
RCD Protected	No
Application	Mobile phone chargers, including those with a USB connectivity, Household entertainment (TVs, satellite boxes, routers etc.), Industrial machines and equipment, Office desks (Monitors, computers, phones), Any electrical device needed to be powered by the mains

Electrical Specifications

Mains Plug Type	Type G - British BS1363
Socket Type	Type G - British
Voltage Rating	250V
Current Rating (Unwound)	13A
Frequency	50/60Hz

Mechanical Specifications

Cable Length	1m
Cross Sectional Area	1.25 mm ²

Operation Environment Specifications

Operating Temperature	-20°C to +80°C
-----------------------	----------------


Approvals

Compliance/Certifications	EN61340
---------------------------	---------





Assembly of accessories:

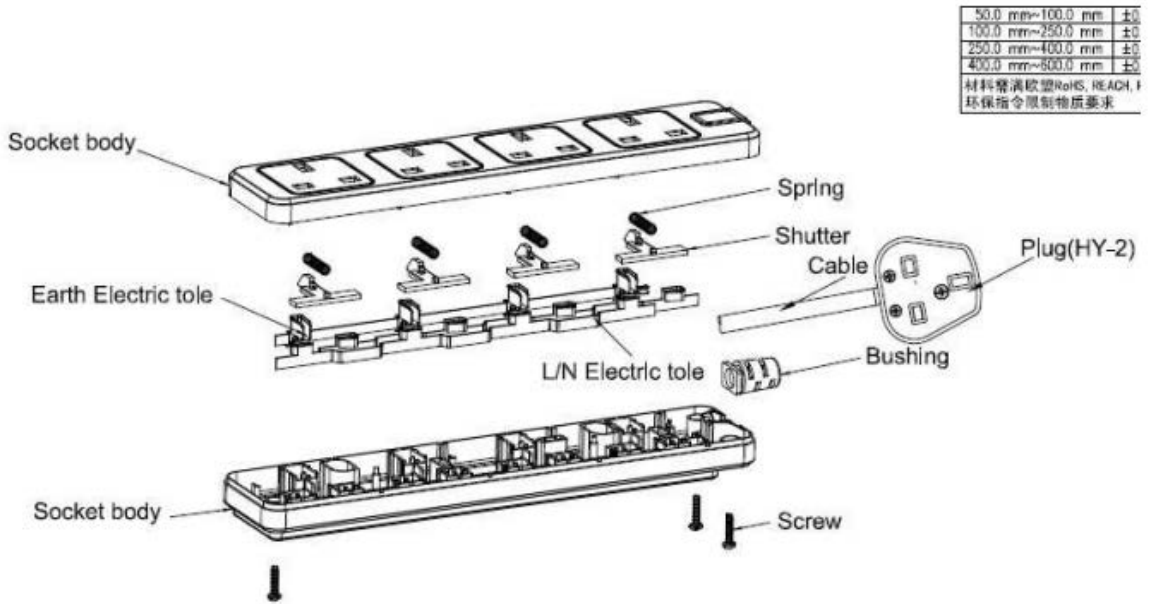

50.0 mm~100.0 mm	±0
100.0 mm~250.0 mm	±0
250.0 mm~400.0 mm	±0
400.0 mm~800.0 mm	±0

材料符合欧盟RoHS, REACH, I
环保指令限制物质要求