

CORUM COLOUMBUS SLIM AND VISUALLY APPEALING EXTERNAL LUMINAIRE



Corum Columbus

PRODUCT OVERVIEW

Highly energy efficient, yet providing a pleasant and uniform light, the Columbus range of bulkhead luminaires is vandal resistant and ideal for wall or ceiling mounting.

The poured gasket seal provides an IP65 rating and protects against abuse, while a screwed-down polycarbonate diffuser and a rigidly constructed polycarbonate base and a strong, symmetrical shape make these luminaires exceptionally robust.


The slim, visually appealing profile of the Columbus that has always been popular is now enhanced by the uniform light achieved through EdgeLED™ technology - there's no requirement for an opal diffuser as the light guide itself provides a pleasant, even light without bright spots.

PRODUCT FEATURES

- Robust Polycarbonate body in black or white
- IP65 rating – formed-in-place foam gasket seal protects against dust and water
- High-impact clear prismatic polycarbonate diffuser
- One-component hinged gear tray incorporating both EdgeLED™ light guide and driver for swift and easy installation
- Highly energy efficient EdgeLED™ optical system with a life span of 30,000 hours (L70)
- Flush fit to fixing surface ensures vandal resistance
- Security screws available
- 5 year warranty



DIMENSIONS

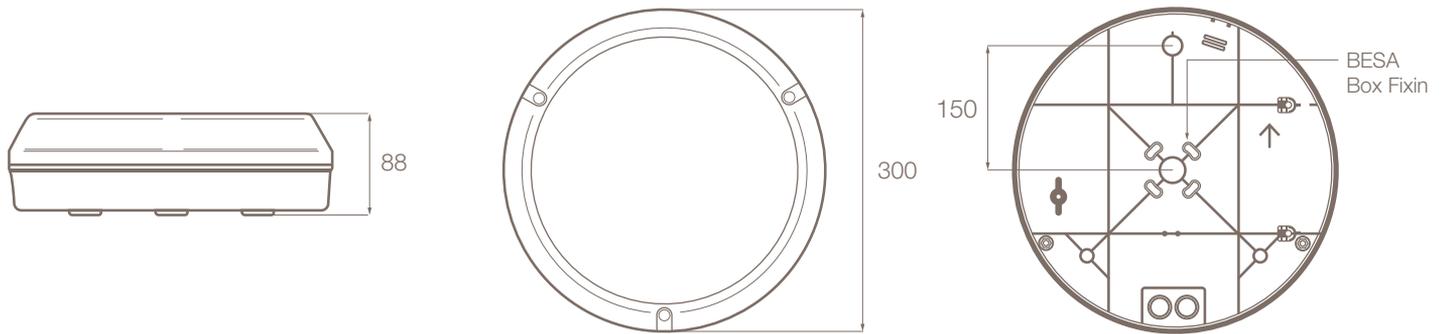

TECHNICAL INFORMATION

Corum Range Columbus		
Lumen Output (Lumens)	800	1,400
System Power Consumption (W)	10	20
Colour Temperature (K)	4,000	4,000
CRI (Ra)	>80	>80
Life (L85 Hours)	30,000 (L70)	30,000 (L70)
Efficacy (Lumens Per Circuit Watt)	80	70
Specification Options:		
3hr Emergency	✓	✓
Auto Test	✓	✓
Microwave Sensor	✓	✓
Photocell	✓	✓
Dali	✓	✓
Corridor Function	✓	✓
Dimming	✓	✓
Weight	1.3kg	
Dimensions (mm)	Ø 300 x 88mm	
Mounting Type	Wall & Ceiling	

LIGHT DISTRIBUTION

