


SIVACON, Roof, Closed, IP55, W: 1200 mm, T: 1000 mm, zinc-plated

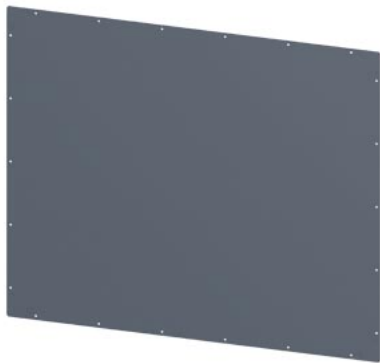

Model			
product brand name		SIVACON	
product designation		top plate	
design of the product		Closed	
design of the surface		zinc plated	
design of the product EMC version		No	
Protection class			
protection class IP		IP55	
Suitability			
suitability for use for outside use		No	
Product details			
product component			
● cable entry	No		
● ventilation	No		
Mechanical Design			
width		1 200 mm	
depth		1 000 mm	
net weight		14.3 kg	
material		steel	
Approvals Certificates			
General Product Approval		Test Certificates	other



[Special Test Certificate](#)

[Confirmation](#)

[Miscellaneous](#)

other	Environment
-------	-------------

[Miscellaneous](#)



[Environmental Confirmations](#)

Further information

Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>
Information- and Downloadcenter (Catalogs, Brochures,...)
<http://www.siemens.com/lowvoltage/catalogs>
Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1020-2UD11-0A>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8MF1020-2UD11-0A>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1020-2UD11-0A

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

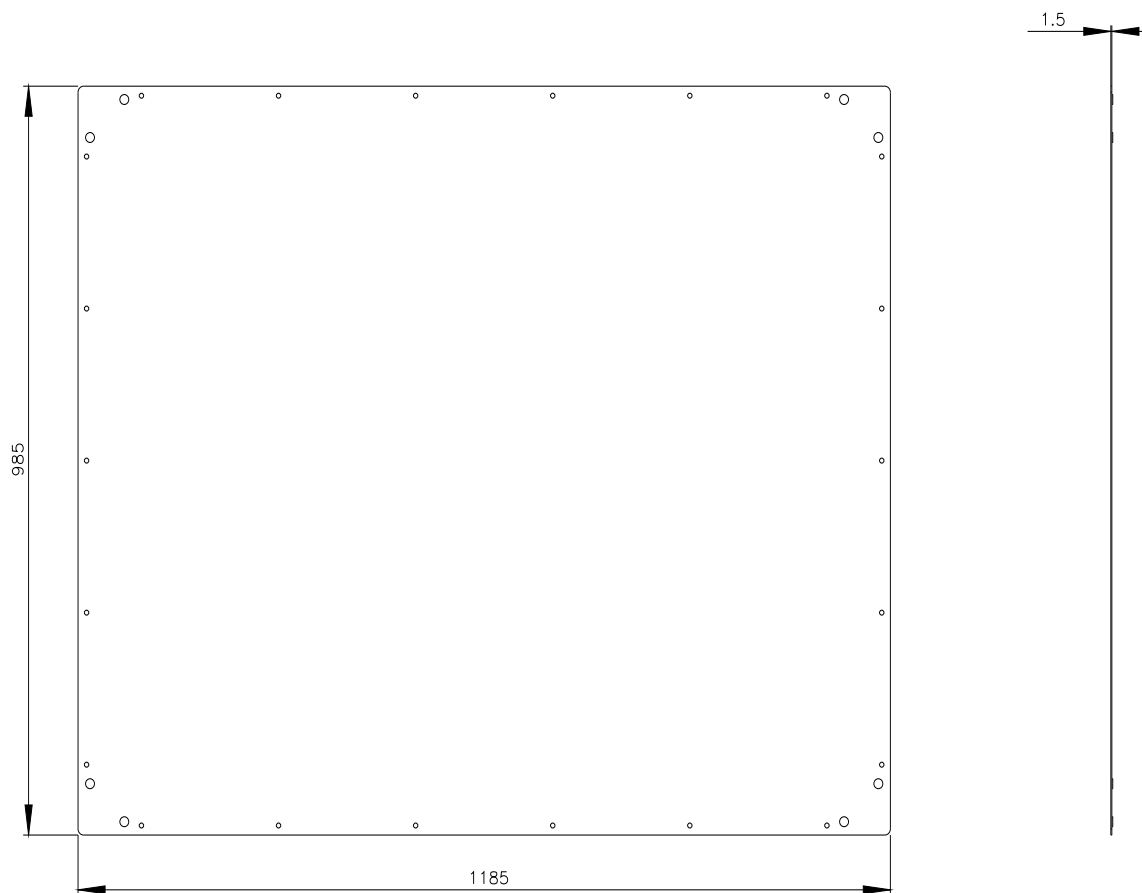

last modified:

7/24/2023 

