



Datasheet

USB A Power Adapter

5Vdc 5W UK Plugtop

RS Stock No.: 8280210

ENGLISH




Features

- Universal AC Input
- UK Plugtop
- Small & Compact Design
- USB A Output
- Over Voltage, Over Current & Over Temp. Protections
- ErP Level V
- RoHS Compliant
- MTBF >50,000 hours

RS Stock Number	Manufacturers P/N	Output Voltage	Output Current (Min)	Output Current (Max)	Power (Watts)	Line Regulation	Voltage Tolerance	Ripple & Noise (mV- p-p)
8280210	T4836ST	+/- 5Vdc	0A	1A	5W	+/-1%	+/-5%	100mV

Input

- Rated Input 100-240Vac
- Rated Input Frequency 50-60Hz
- Input Current 300mA
- Inrush Current 75A at 240Vac
- Efficiency >60%
- UK Plugtop

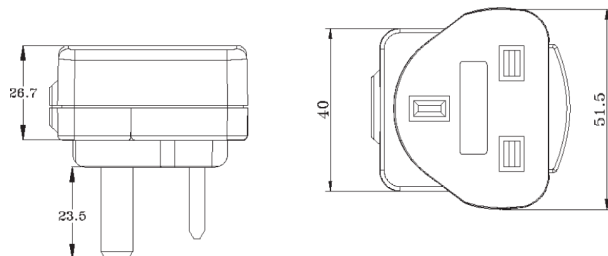


Output

- USB Output

Environmental

- Operating Temperature -20°C to 45°C
- Storage Temperature -10°C to 75°C
- Operating Humidity 20% to 80%
- Storage Humidity 20% to 80%

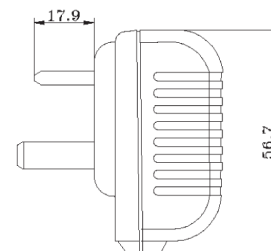

Casing

- Dimensions 51.5mm x 56.7mm x 32.5mm
- Weight 82g (approx.)

