


Produktdatenblatt

LBCR 30 D-2LS

Geschlossenes Linearkugellager, beidseitig abgedichtet

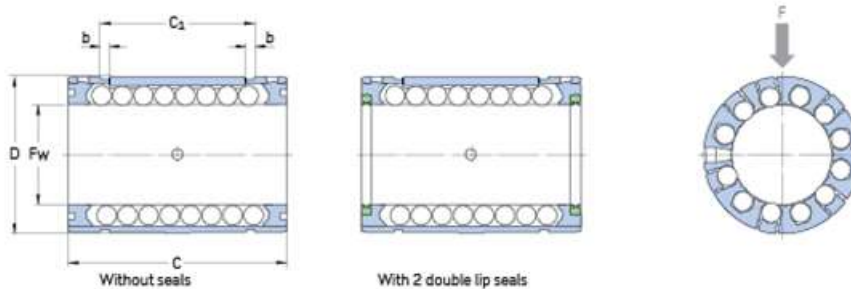

Ersatz für LBCR 30 A-2LS

Fw:	30
D[mm]:	47
C[mm]:	68
C1[mm]:	51.7
b[mm]:	1.85
Kugelreihen [#]:	6
Cmin[N]:	4800
Cmax[N]:	7100
C0min[N]:	3550
C0max[N]:	5700
vmax[m/s]:	5

Datum: 19/05/2020

The contents of this report are the copyright of the publisher and may not be reproduced (even extracts) unless permission is granted. Every care has been taken to ensure the accuracy of the information contained in this report but no liability can be accepted for any loss or damage whether direct, indirect or consequential arising out of the use of the information contained herein.

Produktdatenblatt

LBCR 30 D-2LS

Geschlossenes Linearkugellager, beidseitig abgedichtet

amax[m/s ²]:	100
Gewicht [kg]:	0.122

Datum: 19/05/2020

The contents of this report are the copyright of the publisher and may not be reproduced (even extracts) unless permission is granted. Every care has been taken to ensure the accuracy of the information contained in this report but no liability can be accepted for any loss or damage whether direct, indirect or consequential arising out of the use of the information contained herein.