


## Prohibition sign - US-PML-P200 (D50) CUS - 1014223

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)

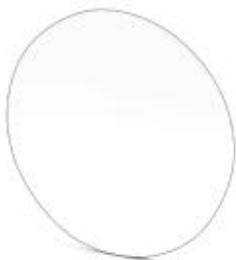

Prohibition sign, can be ordered: By card, white, labeled according to customer specifications: Blank, Mounting type: Adhesive, Diameter: 50 mm, Lettering field: d: 50 mm

### Why buy this product

- UniSheet - stick-on prohibition sign, unprinted



### Key commercial data

Packing unit	1
GTIN	 4 046356 786782
Custom tariff number	39203000

### Technical data

#### Dimensions

Width (a)	50 mm
Diameter	50.00 mm

#### Ambient conditions

Ambient temperature (operation)	-40 °C ... 90 °C
---------------------------------	------------------

#### General

Color	white
Type	Round
Components	Silicone-free
Material	PVC
Wipe resistance	DIN EN 61010-1 (VDE 0411-1)
Printing	Blank
Number of individual labels	4
Marking mounting type	Adhesive

## Prohibition sign - US-PML-P200 (D50) CUS - 1014223

### Classifications

#### eCl@ss

eCl@ss 4.0	27141199
eCl@ss 4.1	27141199
eCl@ss 5.0	27371301
eCl@ss 5.1	27371301
eCl@ss 6.0	27371301
eCl@ss 7.0	27371301

#### ETIM

ETIM 3.0	EC000712
ETIM 4.0	EC002498
ETIM 5.0	EC000761

#### UNSPSC

UNSPSC 6.01	43172501
UNSPSC 7.0901	43212107
UNSPSC 11	43172501
UNSPSC 12.01	43212107
UNSPSC 13.2	43212107