



Brand of NTN corporation

Technical data

EXFCE209L3

Bearing units




Grey cast housing, radial insert ball bearing with eccentric locking collar, triple lip seal

KIT CONTENT

EX209G2L3, FCE209

VISUAL (S)

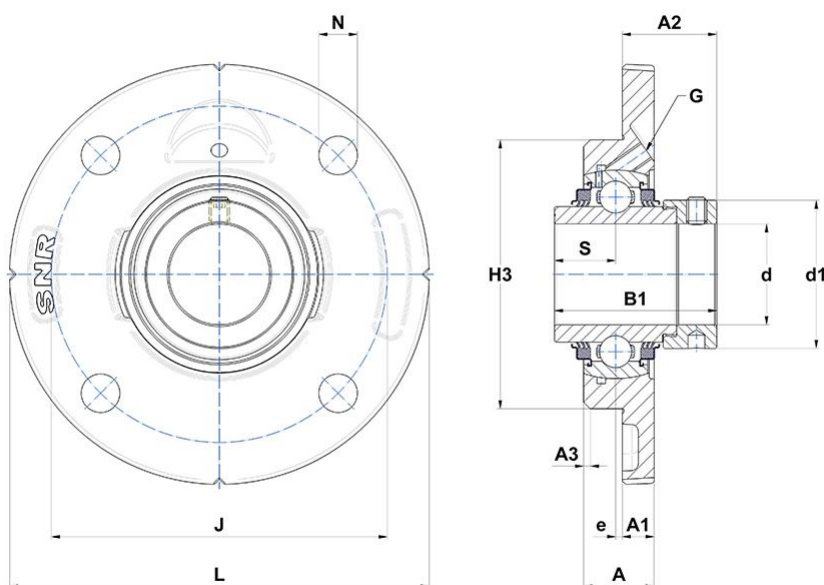

PRODUCT DEFINITION

Brand	SNR
A - Housing height	25 mm
A1 - Housing foot height / flange height	12 mm
A2 - Total height from mounting surface	32,9 mm
A3 - Centering depth / chamfer dimension	2 mm
B - Width of Inner Ring	42,8 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

B1 - Overall width Inner Ring	56,3 mm
d - Shaft diameter	45 mm
d1 - Outer dia of eccent. Lock. collar / nut of adapter sleeve	62 mm
e - Distance mounting surface to bearing center	-2 mm
G - Grease fitting	M6x1
H3 - Centering dia	105 mm
J - Mounting holes distance	130 mm
L - Housing width / diameter	155 mm
N - Mounting hole dimension	14 mm
S - Distance front side/bearing centre	21,4 mm

PRODUCT PERFORMANCE

C - Dynamic load rating	31850000 mN
C0 - Static load rating	20800000 mN
Operating temperature min.	253,15 °K
Operating temperature max.	373,15 °K

OTHER FEATURES

Mass	2,05 kg
Recommended tightening torque for set screw	11.5 N-m

