



M12™ HEATED PUFFER JACKET - BLACK



**Runtime 11
hours**



**Optimized
battery pocket**




**Change heat
setting
dualzone**



Dryer safe



Heat levels

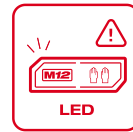

**LED switch
active dualzone**



**Axis™ ripstop
polyester**

FEATURES

- M12™ Heated Jacket powered by an M12™ battery with carbon fibre heating elements creates and distributes heat to chest, back and shoulders
- Superior run time, up to 11 hours of heat on a single battery charge of an M12™ REDLITHIUM™ 3.0 Ah battery pack
- Lightweight and highly durable ripstop polyester provides a slim design that can be worn as an outer-shell or a mid-layer (100% Polyester outer and inner shell)
- Reinforced high-wear zones protect from abrasion and tears
- Provides comfort and durability in harsh, rainy or windy environments
- Optimised hidden battery pocket to place M12™ battery in front or rear for increased comfort
- Multiple heating zones - 5 sewn in carbon fibre heating zones distribute heat to core body areas

TECHNICAL INFORMATION

Article number 4932480071

Pack quantity 1

CARE INSTRUCTIONS



WASH AT 40 DEGREES



DO NOT BLEACH

**STAY SAFE.
STAY PRODUCTIVE.**



Disclaimer

Information present within
this sheet was correct at
the date of issue.

Techtronic Industries GmbH

71364 Winnenden
Germany

uk.milwaukeetool.eu



M12™ HEATED PUFFER JACKET - BLACK



STORAGE INSTRUCTIONS

Cool down product before storing. Remove the battery and battery holder before storing. Do not allow the cords to be pinched. Do not store the battery pack together with metal objects (short circuit risk). Never break open battery packs and chargers and store only in dry rooms. Keep dry at all times.

USAGE INSTRUCTIONS

Disclaimer

Information present within this sheet was correct at the date of issue.

Techtronic Industries GmbH

71364 Winnenden
Germany

uk.milwaukeetool.eu

STAY SAFE.
STAY PRODUCTIVE. 