

Pushbutton Switch

Features

- For harsh environments
- Resistant to salt spray
- Excellent tactile feedback
- Long lifetime




Specification

Current Rating	2 A
Voltage Rating	36 V
Contact Resistance	50 mOhm max.
Insulation Resistance	1 GOhm min. @ 500 V
Dielectric Strength	2 kV RMS, 50 ~ 60 Hz
Operating Temperature	-20 ... 55 °C
Switching Circuit	OFF-(ON)
Contact Configuration	1NO
Mounting Type	Panel Mount
Termination Type	Soldering Lugs
Protection Rating	IP67
Torque	5 ... 14 Nm max. Applied to Nut
Operating Force	5 N

Material Specification

Bushing	Zinc Alloy, Nickel Plated
Contact	Silver Alloy
Nut	Nickel Plated Brass
Button	PBT
Base	PBT
Button Colour	Green

Drawing

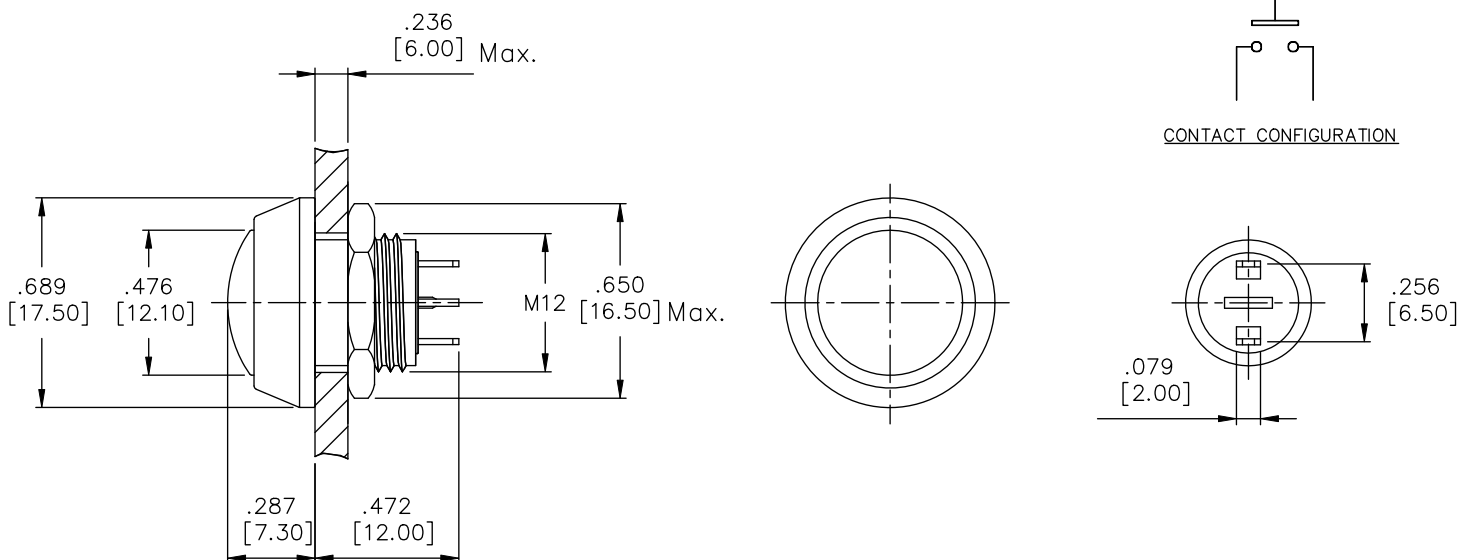

Art Nr.
RND 210-00729