



Brand of NTN corporation

Technical data

UCP326

Bearing units




Grey cast housing, radial insert ball bearing with socket set screws, seal with slinger

KIT CONTENT

UC326G2, P326

VISUAL (S)

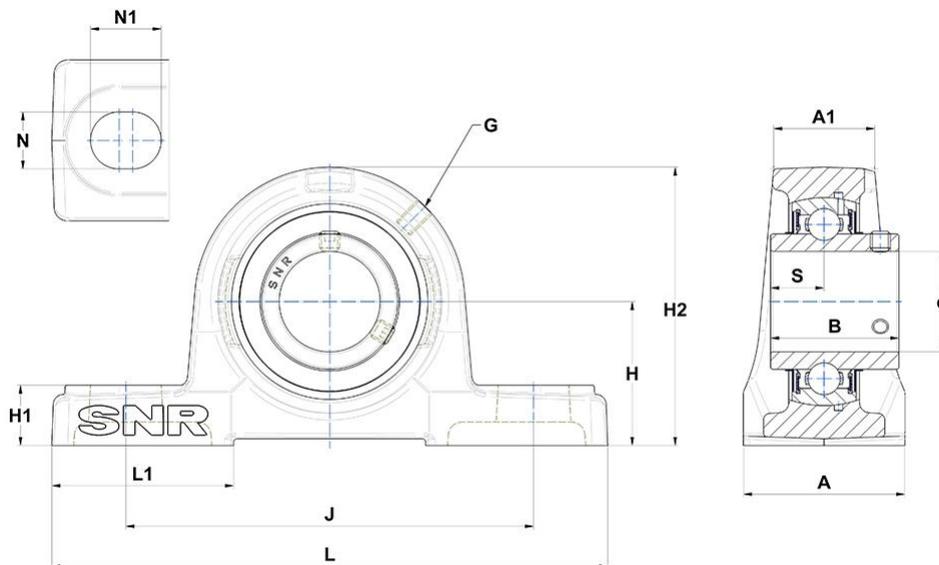

PRODUCT DEFINITION

| | |
|--------------------------------|--------|
| Brand | SNR |
| A - Housing width | 140 mm |
| A1 - Housing top width | 94 mm |
| B - Width of Inner Ring | 135 mm |
| d - Shaft diameter | 130 mm |
| G - Grease fitting | M10x1 |



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
 S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
 SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

| | |
|--|--------|
| H - Distance mounting base to centerline spheric. seating diam. | 180 mm |
| H1 - Housing foot height | 75 mm |
| H2 - Housing height | 355 mm |
| J - Mounting holes distance | 480 mm |
| L - Housing length | 600 mm |
| L1 - Housing foot length | 140 mm |
| N - Mounting hole dimension | 40 mm |
| N1 - Mounting hole length | 55 mm |
| S - Distance front side/bearing centre | 54 mm |

PRODUCT PERFORMANCE

| | |
|-----------------------------------|--------------|
| C - Dynamic load rating | 252000000 mN |
| C0 - Static load rating | 242000000 mN |
| Operating temperature min. | 253,15 °K |
| Operating temperature max. | 373,15 °K |

OTHER FEATURES

| | |
|--|---------|
| Mass | 75 kg |
| Recommended tightening torque for set screw | 120 N-m |

