


C5D82UXXX

(Mueller Blue-Flex™, M12 Cordset, 5 Position, 22 AWG, Female Right-Angle to Free End)

Mueller Blue-Flex™

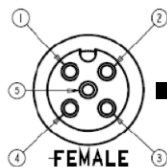

| Pin Out | | |
|---------|-------|----------|
| End 1 | Color | End 2 |
| 1 | Brown | Free End |
| 2 | White | |
| 3 | Blue | |
| 4 | Black | |
| 5 | Grey | |

- Mueller's C5D82UXXX is part of Mueller Blue-Flex's™ instrumentation cable offering. The cable is an M12 with a right-angle female connector on one end and free at the other
- Keyway – A coding
- Utilizes the Mueller Blue-Flex™ cable – 5 conductor, 22AWG, unshielded, silicone outer jacket and inner conductor jacket for maximum flexibility.
- Ratings:
 - Current: 4A
 - Voltage: 60 V AC/DC
- Material
 - Coupling Nuts (anti-vibration) – Nickel Plated Brass (also available in stainless steel)
 - Pins/Contacts – Gold Plated Brass
- Length: The "U" in the model number represents unit of measurement.
Either: Meters (M), Feet (F)
- Length: The "XXX" in the model number represents length. Standard lengths are 2, 5, and 10 meters. Any other lengths available upon request.
- Meets Standard: IEC 61076-2-101
- Protection Class: IEC IP68
- RoHS 3 Compliant