

Features

- HDMI Male
- HDMI Male
- Length: 1.5m
- Black

RS PRO 1.5m Flat HDMI High Speed with Ethernet Cable

RS Stock No.: 0839446



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

HDMI (High Definition Multimedia Interface) is a specification that combines video and audio into a single digital interface for use with DVD players, digital television (DTV) players, set-top boxes, and other audio visual devices.

HDMI supports standard, enhanced, or high-definition video plus standard to multi-channel surround-sound audio.

General Specifications


Connector 1	HDMI
Connector 1 Gender	Male
Connector 2	HDMI
Connector 2 Gender	Male
Cable Length	1.5m
Cable Colour	Black
HDMI Version	High Speed with Ethernet

Approvals

Standards Met	CE UKCA REACH ROHS
---------------	--------------------

Similar Products

Stock No.	Brand	Product Name
0839445	RS PRO	35cm HDMI M to 2x F Splitter Cable
0839449	RS PRO	1m HDMI to HDMI Mini (C) Cable
0839446	RS PRO	1.5m Flat HDMI High Speed with Ethernet Cable
0839447	RS PRO	2m HDMI Mini (C) Cable
0839444	RS PRO	2.5m HDMI To DVI D Cable

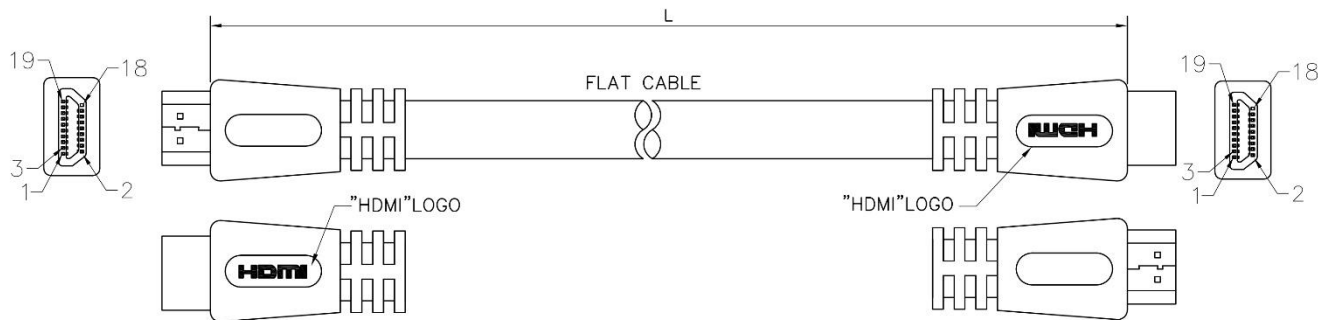

HDMI(M)(P1)
(MOLDING BLACK COLOR)

HDMI(M)(P2)
(MOLDING BLACK COLOR)

PIN ASSIGNMENT(1.4V)

HDMI19(M)		HDMI19(M)	
3		3	TMDS data2-
1		1	TMDS data2+
2		2	TMDS data2 Shield
6		6	TMDS data1-
4		4	TMDS data1+
5		5	TMDS data1 Shield
9		9	TMDS data0-
7		7	TMDS data0+
8		8	TMDS data0 Shield
12		12	TMDS Clock-
10		10	TMDS Clock+
11		11	TMDS Clock Shield
19		19	HPD/HEAC-
14		14	Utility/HEAC+
17		17	DCC/CED/HEAC GND
13	BROWN	13	CEC
15	RED	15	SCL
16	BLUE	16	SDA
18	YELLOW	18	+5V Power
SHELL	Braid	SHELL	

NOTE:

- CABLE: 28AWG,UL20276,AL-FOIL, (#28*1P+D)*5PCS+#30*4C+D,FLAT CABLE,BLACK COLOR, OD=3.4*13±0.2mm,PVC JACKET(single shielded)
- LENGTH:L.
- CONNECTORS: HDMI19P(M)*2PCS(BLACK INSULATOR)(GOLD PLATE SHELL).
- MOLD: MOLDING TYPE.
- CONTACTS:
- Test machine test condition.
 - 100% OPEN,SHORT&INTERMITTANCE TEST.
 - CONDUCTOR RESISTANCE: 3ohms MAX:
 - INSULATION RESISTANCE: 5M Min/,10ms:
- ALL MUST BE MEET ON ROHS COMPLIANT.