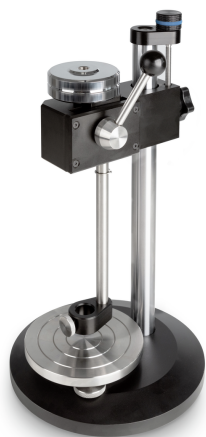


# KERN TI-HEA

Test stand for hardness testing Shore A and D

**KERN**

## Pictograms

### STANDARD



## Category

|                  |                         |
|------------------|-------------------------|
| Brand            | Sauter                  |
| Product category | Hardness testing        |
| Product group    | Manual Shore test stand |
| Product family   | TI-HE                   |

## Measuring System

|                                 |         |
|---------------------------------|---------|
| Test force Hardness measurement | 10 N    |
| Hardness scales                 | Shore A |

## Construction

|                                                       |                  |
|-------------------------------------------------------|------------------|
| Dimensions completely mounted (W×D×H)                 | 200×200×390 mm   |
| Base plate diameter (Ø)                               | 115 mm           |
| Material                                              | steel, lacquered |
| Material housing                                      | steel, lacquered |
| Test object height [Max]                              | 50 mm            |
| Traverse distance with lever movement / release [Max] | 20 mm            |

## Environmental conditions

|                           |       |
|---------------------------|-------|
| Storage temperature [Max] | 40 °C |
|---------------------------|-------|

## Packing & Shipping

|                              |                |
|------------------------------|----------------|
| Delivery time                | 1 d            |
| Dimensions packaging (W×D×H) | 250×250×400 mm |
| Net weight                   | 5,62 kg        |
| Shipping method              | Parcel service |
| Net weight approx.           | 6 kg           |
| Gross weight approx.         | 7 kg           |
| Shipping weight              | 6,3 kg         |