

2345986-1 ✓ ACTIVE

TE Internal #: 2345986-1

C, 3.1 Gen 2, Receptacle, Top Mount, 1 Port, Right Angle, Reel, Offset, Surface Mount, Cable-to-Board / Wire-to-Board, Printed Circuit Board

[View on TE.com >](#)



Connectors > Audio & Video Connectors > USB Connectors



USB Type: C

USB Version: 3.1 Gen 2

Connector & Housing Type: Receptacle

Number of Ports: 1

PCB Mount Location: Top Mount

Features

Product Type Features

Grounding Options	PCB Ground
Integral Locking Latch	Without
USB Type	C
USB Version	3.1 Gen 2
Connector & Housing Type	Receptacle
Connector System	Cable-to-Board, Wire-to-Board
Connector & Contact Terminates To	Printed Circuit Board

Configuration Features

Number of Ports	1
-----------------	---

Body Features

Shell Plating Material	Nickel
Offset	1.63 mm
Shell Plating Finish	Matte

Contact Features



	5 µin
Contact Mating Area Plating Material	Gold Flash
Contact Current Rating (Max)	5 A

Termination Features

Termination Method to PCB	Surface Mount
---------------------------	---------------

Mechanical Attachment

Locking Feature	Without
PCB Mount Alignment Type	Locating Posts
PCB Mount Location	Top Mount
PCB Connector Seating	Offset
Connector Mounting Type	Board Mount

Housing Features

Housing Color	Black
Housing Material	Liquid Crystal Polymer (LCP)
Body Orientation	Right Angle

Usage Conditions

Soldering Temperature (Max)	255 °C[491 °F]
Mating Cycles (Max)	10000
Operating Temperature Range	-40 – 85 °C[-40 – 185 °F]

Operation/Application

Assembly Process Feature	Without Pick and Place Cover
Circuit Application	Power & Signal

Industry Standards

UL Flammability Rating	UL 94V-0
------------------------	----------

Packaging Features

Packaging Quantity	900
Packaging Method	Reel

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Not Yet Reviewed



China RoHS 2 Directive MIIT Order No 32, 2016	有害物质含量符合标准要求 No Restricted Substance(s) Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JUNE 2025 (250) Candidate List Declared Against: JUNE 2025 (250) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not reviewed for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts

TE Part # 2480842-1
USB C Charge-only, 6 Pin, Vert, Long, Lock

TE Part # 2480803-1
USB C Charge-only, 6 Pin, Vertical, Short

TE Part # 2480843-1
USB C Charge-only, 6 Pin, Mid, 3u GF



TE Part # 2305018-2
USB TYPE C, REC IPX8 ON BOARD DUAL SMT

TE Part # 2479774-2
USB C Charge-only, 6 Pin, Top, 3u GF

TE Part # 2479774-1
USB C Charge-only, 6 Pin, Top, 1u GF

TE Part # 2480790-1
USB C Charge-only, 6 Pin, Vertical, Long

Customers Also Bought

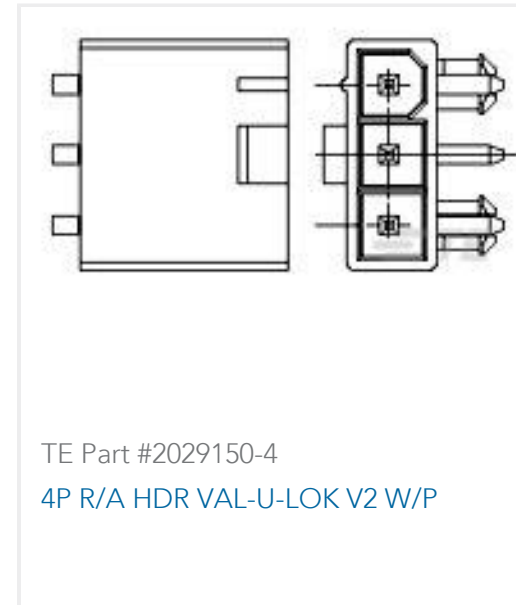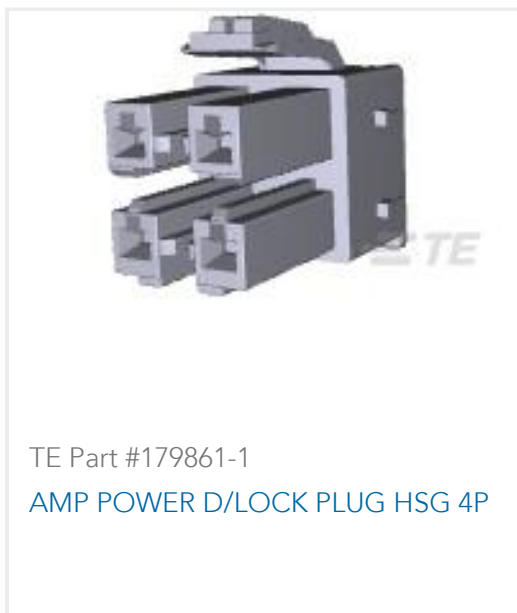

Documents

Product Drawings

[USB TYPE C 3.1 TOP MOUNT DUAL SMT 1.63CH](#)

English

CAD Files

[3D PDF](#)

3D

Customer View Model

[ENG_CVM_CVM_2345986-1_1.2d_dxf.zip](#)

English

Customer View Model

[ENG_CVM_CVM_2345986-1_1.3d_igs.zip](#)

English

Customer View Model

[ENG_CVM_CVM_2345986-1_1.3d_stp.zip](#)

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications



Product Specification

English