


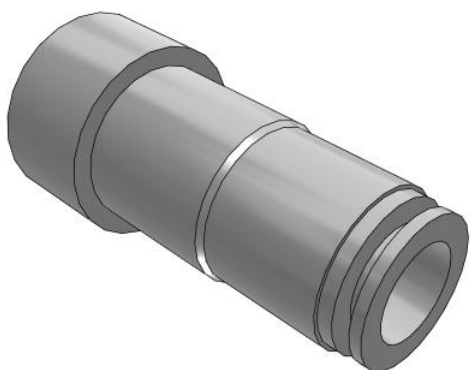

## KK130S-\*H, S-Couplers, Straight Type with One-touch Fitting KK130S-12H


### Datasheet

- Straight Type with One-touch Fitting.
- Applicable Tubing O.D.: ø6, ø8, ø10, ø12, ø1/4, ø5/16, ø3/8, ø1/2.

### Standard specifications

|                             |                                                                                 |
|-----------------------------|---------------------------------------------------------------------------------|
| Type                        | S (Socket)                                                                      |
| Applicable Tubing O.D.      | ø12 mm                                                                          |
| Pressure medium             | Air                                                                             |
| Maximum operating pressure  | 1.5 MPa                                                                         |
| Minimum operating pressure  | 0 MPa                                                                           |
| Proof pressure              | 2 MPa                                                                           |
| Maximum ambient temperature | 80 °C                                                                           |
| Minimum ambient temperature | -20 °C (No freezing)                                                            |
| Sealing principle           | Male thread with sealant                                                        |
| Plating                     | Sleeve: Electroless nickel plated<br>Other external metal parts: Zinc chromated |
| Weight                      | 0.080 Kg                                                                        |

## Dimensions

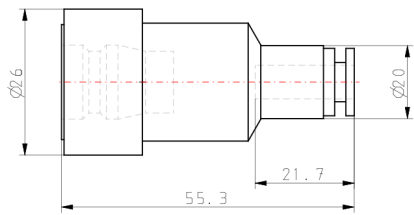

## Additional information

Catalogue

[KK130-B\\_EU.pdf](#)