


Datasheet


RS Pro V-Ring Seals



Stock no.	Reference	Shaft Dia. C (mm)	Outside Dia. of Seal (mm)	Seal dia. d1 (mm)	Profile height W (mm)	Profile Width B2 (mm)	Total Width B (mm)	Max. Permissible d2 (mm)	Min. Permissible d3 (mm)	Fitted Width B1 (mm)
749575	V6A	5.5 - 6.5	9.5 - 10.5	5	2	2.4	3.7	C + 1	C + 6	3.0 ± 0.4
749581	V10A	9.5 - 11.5	15.5 - 17.5	9	3	3.4	5.5	C + 2	C + 9	4.5 ± 0.6
749597	V12A	11.5 - 12.5	17.5 - 18.5	10.5	3	3.4	5.5	C + 2	C + 9	4.5 ± 0.6
749604	V14A	13.5 - 15.5	18.5 - 21.5	12.5	3	3.4	5.5	C + 2	C + 9	4.5 ± 0.6
749610	V16A	15.5 - 17.5	21.5 - 23.5	14	3	3.4	5.5	C + 2	C + 9	4.5 ± 0.6
749626	V20A	19 - 21	27 - 29	18	4	4.7	7.5	C + 2	C + 12	6.0 ± 0.8
749632	V22A	21 - 24	29 - 32	20	4	4.7	7.5	C + 2	C + 12	6.0 ± 0.8
749648	V25A	24 - 27	32 - 35	22	4	4.7	7.5	C + 2	C + 12	6.0 ± 0.8
749654	V30A	29 - 31	37 - 39	27	4	4.7	7.5	C + 3	C + 12	6.0 ± 0.8
749660	V35A	33 - 36	41 - 44	31	4	4.7	7.5	C + 3	C + 12	6.0 ± 0.8
749676	V40A	38 - 43	48 - 53	36	5	5.5	9	C + 3	C + 15	7.0 ± 1.0
749682	V45A	43 - 48	53 - 58	40	5	5.5	9	C + 3	C + 15	7.0 ± 1.0
749698	V50A	48 - 53	58 - 63	45	5	5.5	9	C + 3	C + 15	7.0 ± 1.0

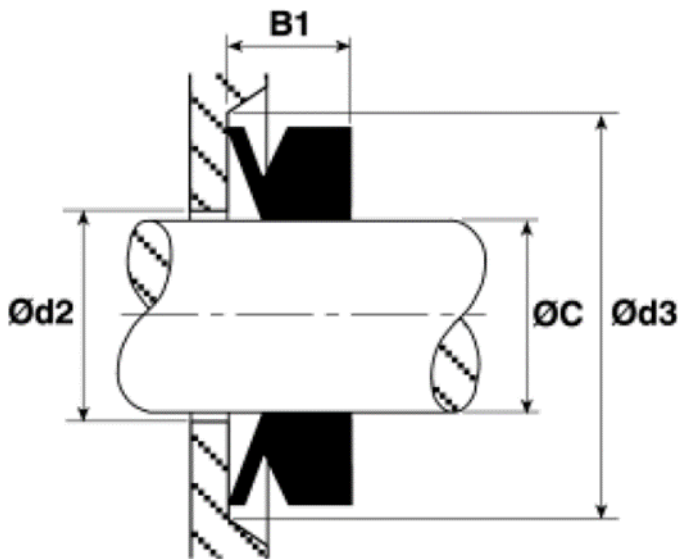

Application

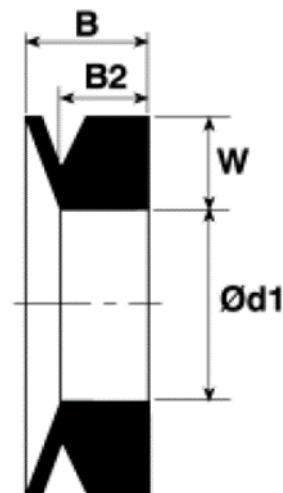

Profile