


Connection Units

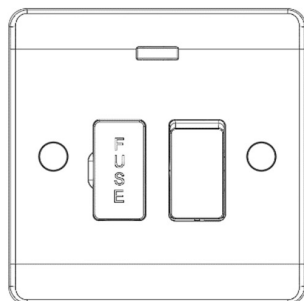

Description

This uniquely shaped range is easy to install with clear bold terminal markings and is supplied in individual protective polybags suitable for display.

This range includes flex outlet and neon versions.

Features

- Contemporary designed profile
- Concave rockers
- Only one size 4mm screwdriver needed
- Terminals have clear bold markings
- Neon versions available
- Neon leads enclosed
- Fuse carrier can be locked in the out position
- 2 earth terminals
- Terminals have large lead-ins
- 25-year guarantee

Range

Unswitched spur	VP1360
Unswitched spur with neon	VP1361
Unswitched spur with bottom flex outlet	VP1364
Switched spur	VP1370
Switched spur with neon	VP1371
Switched spur with bottom flex outlet	VP1374
DP switched, neon & bottom flex outlet	VP1375

Technical Specification

Voltage rating	250Vac
Current Rating	13A
Contact gap	3mm
Size	86 x86 x 7mm (H x W x D)
Front plate material	Urea formaldehyde

Urea flammability classification UL94 grade V-0

No user serviceable parts, except BS 1362 fuse

Standards

- BS 1363-4: A4
- Fuses – BS 1362

Back Boxes

Minimum recommended depth

	Metal Flush 25mm	Dry lining 35mm	Surface	
			25mm	33mm
1g	DB162	DB2540	VP1221	VP1222

Terminal Capacity

	2.5mm ²	4mm ²	6mm ²	10mm ²
L & N	4	2	2	1