

Actuator

61-
3440.4/D

Distribution by
Rs-online



<https://rs-online.eao.com/p/61-3440.4/D>

Your product:



61-3440.4/D Actuator

MOUNTING

Mounting type: Panel mounting

OPERATING-/INDICATION PART

Lens colour: Red

Lens material: Plastic

Lens illumination: Non illuminated

Lens shape: Mushroom-head

Lens optics: opaque

MECHANICAL CHARACTERISTIC

Switching action: Maintained

Release type: Twist to unlock

Tightening torque: Max. 0.5 Nm

Weight: 0.02 kg

AMBIENT CONDITION

Operating temperature: – 25 °C ... + 55 °C


CERTIFICATE

REACH: REACH compliant


RoHS: RoHS compliant

OTHER


Short Description:	Actuator, Mushroom-head, Non illuminated, Red, Plastic, opaque, Maintained, Twist to unlock
Housing colour:	Yellow
Housing material:	Plastic
Marking:	Arrows
Product attributes:	Twist to unlock clockwise, with fixing nut metal
Wiring diagrams:	

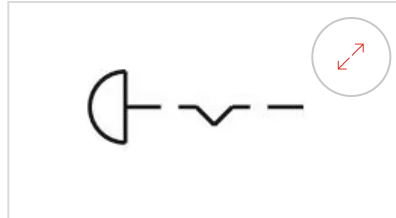

Mounting cut-outs:

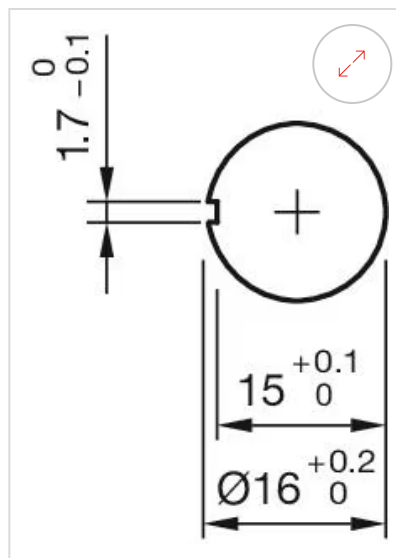

Dimension drawings:

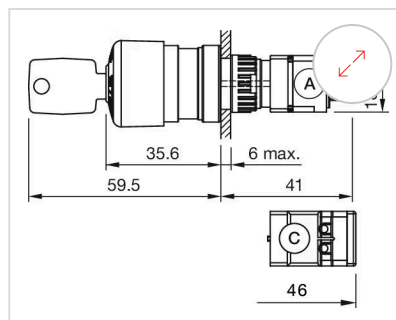

A = Plug-in terminal 2.8 mm x 0.5 mm
C = Screw terminal