

SURGE SUPPRESSOR, VARISTOR,
AC 24...48V, DC 24...70V,
FOR MOTOR CONTACTORS SZ S0,

General technical data:

Product brand name		SIRIUS
Product designation		surge suppressor
Size of the contactor		S0
Design of the surge suppressor		with varistor
Ambient temperature		
<ul style="list-style-type: none"> • during storage 	°C	-40 ... 80
<ul style="list-style-type: none"> • during the operating phase 	°C	-25 ... 60

Control circuit:

Type of voltage / of the controlled supply voltage		AC/DC
control supply voltage frequency		
<ul style="list-style-type: none"> • 1 / rated value 	Hz	50
<ul style="list-style-type: none"> • 2 / rated value 	Hz	60
Control supply voltage / 1		
<ul style="list-style-type: none"> • for DC <ul style="list-style-type: none"> • initial rated value • final rated value • at 50 Hz / for AC <ul style="list-style-type: none"> • initial rated value • final rated value • at 60 Hz / for AC <ul style="list-style-type: none"> • final rated value • initial rated value 	V	24
	V	70
	V	24
	V	48
	V	48
	V	24

Installation/mounting/dimensions:

built in orientation		any
Type of fixing/fixation		clip-on
Width	mm	30
Height	mm	19
Depth	mm	12

Certificates/approvals:

Further information:

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/industrial-controls/catalogs>

Global Industry Mall (Online ordering system)



<http://www.siemens.com/industrial-controls/mall>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<http://support.automation.siemens.com/WWW/view/en/3RT2926-1BB00/all>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)

http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3RT2926-1BB00

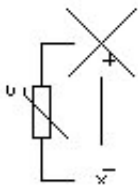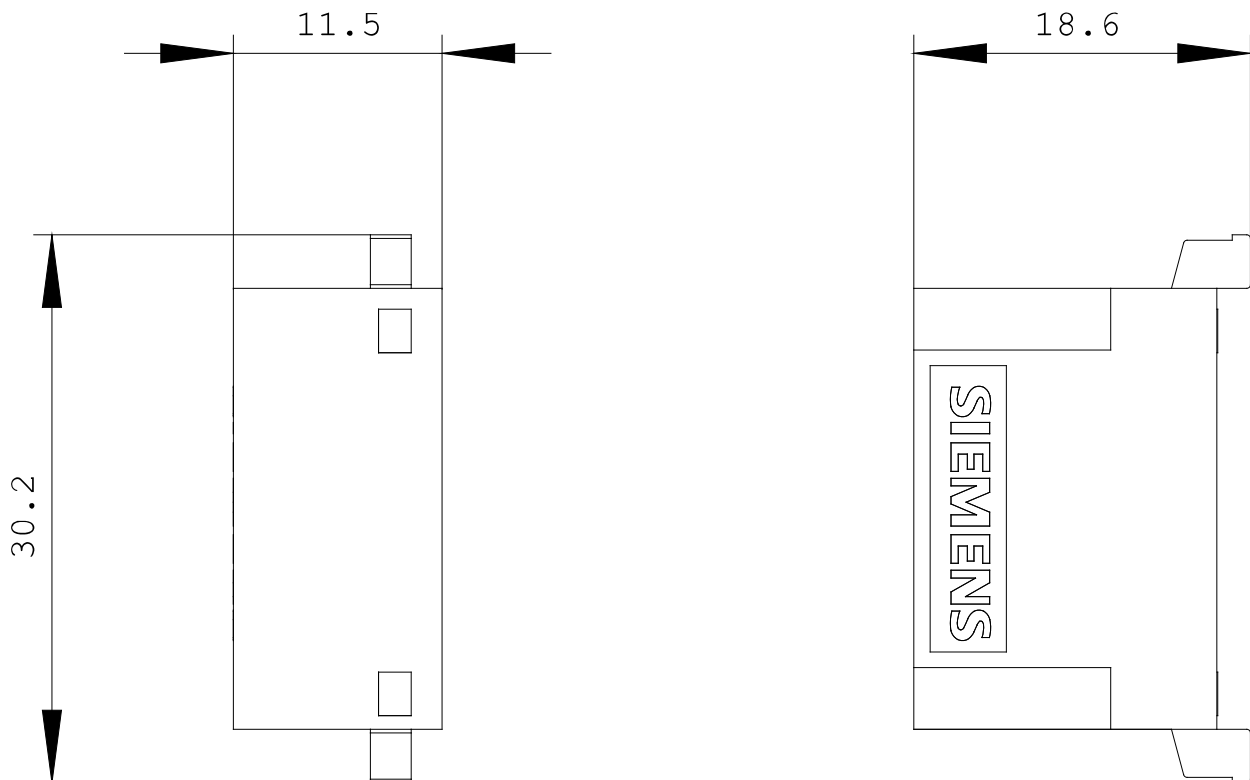

last change:

Apr 26, 2010