


Professionally approved products.

Datasheet

AMPLIMITE HDP,HDF screwlock kit 4-40

RS Stock number [717-4543](#)

Dimensions: mm

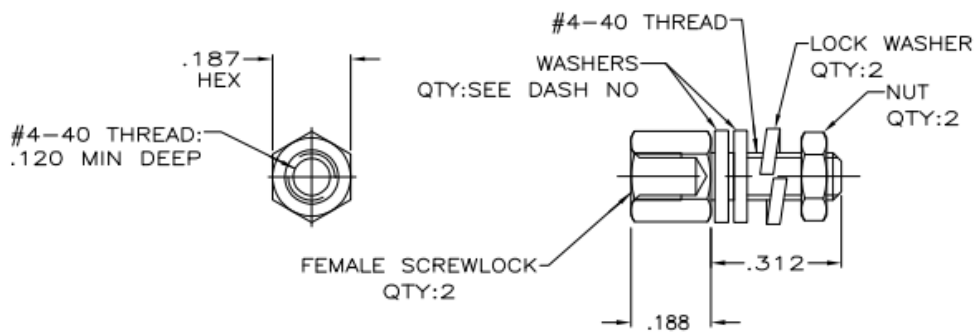

| TOLERANCES UNLESS OTHERWISE SPECIFIED: | | |
|--|---------------|-------------------------|
| 0 PLC | ± - | |
| 1 PLC | ± - | |
| 2 PLC | ± - | |
| 3 PLC | ± .005 | |
| 4 PLC | ± - | |
| ANGLES | | ± - |
| \triangle | 6 | \triangle \triangle |
| \triangle | 4 | \triangle |
| \triangle | 4 | \triangle |
| \triangle | 4 | \triangle |
| \triangle | 4 | \triangle |
| PACKAGING | NO OF WASHERS | FINISH |

Specifications

1. Zinc Plated .000200- .000400 Thick Yellow Chromate Coating
2. Zinc Plated .000200- .000400 Thick Clear Chromate Coating
3. Parts Packaged Unassembled
4. Parts packaged as a unit kit
5. Parts individually bulk packed & shipped as a unit package
6. Chromate finish per ASTM B633 except for use of trivalent chromium to meet RHS regulations

- Materials: Cold Rolled Steel