

Part No. 104102207

Series Series 410 eSafe, DN 10.4

[3D](#)

[PDF](#)

[Inquiry List](#)

Category title

eSafe vented safety coupling

Class title

Female thread

Connection

G 3/4"

Connection type

Standard quick couplings

Nominal flow diameter (mm)

10.4 mm (0.4")

Air flow (l/min)

4000 l/min (141.2 CFM)

Max working pressure (bar)

16 bar (232 PSI)

Min. burst pressure (bar)

140 bar (2030 PSI)

Connection force (N)

140 N

Min temperature (C)

-20°C — +100°C (-4°F — +212°F)

Material standard

Steel/Aluminum

Nipple standard


CEJN original eurostandard 10.4 mm

Series 410 eSafe, DN 10.4

CEJN Original, Eurostandard | Soft-line

eSafe Series 410 is a safety coupling based on CEJN Series 410, a CEJN original and European standard. The Series is one-hand operated and offers long service life. It is a one hand operated safety coupling that vents before disconnection eliminating the risk of hose whip. The fully automatic operation ensures quick and easy handling. It complies with ISO Standard 4414 and has a steel front part as standard.



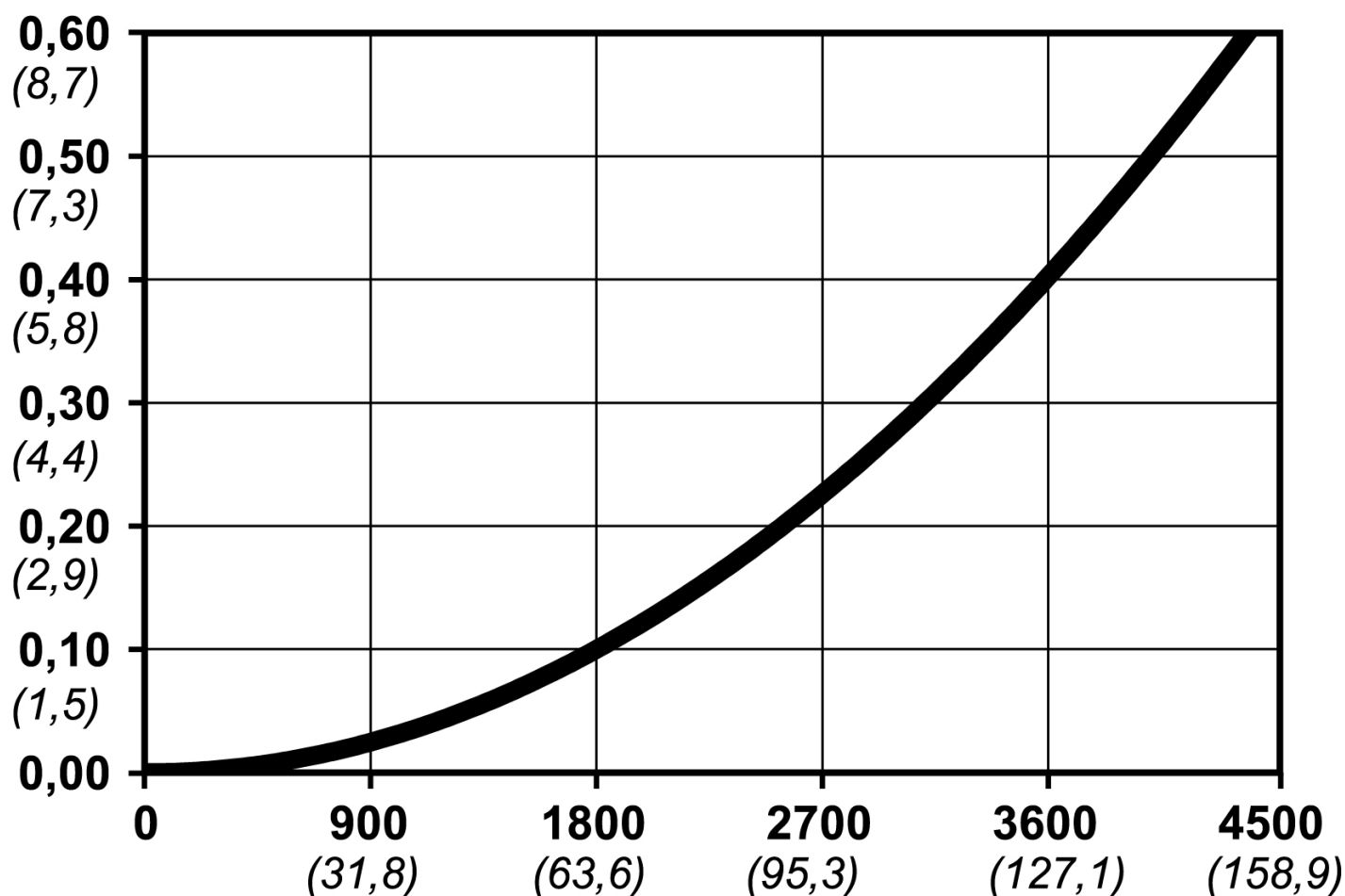

Air Flow

x: Chart flow l/min (CFM)

y: Chart pressure drop bar (PSI)

Check with an authorized CEJN distributor for availability and prices. All measurements are in mm. Other connections and sealing material on request. Some part numbers may be subject to minimum order quantities. CEJN reserves the right to make changes without further notification. Thread connections are listed according to ISO standards, unless stated otherwise.