



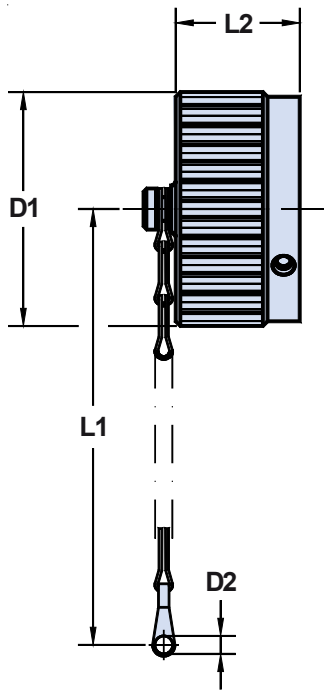

**VG95234 KR**  
**Receptacle Protective Cover**  
**With Stainless Steel Chain**

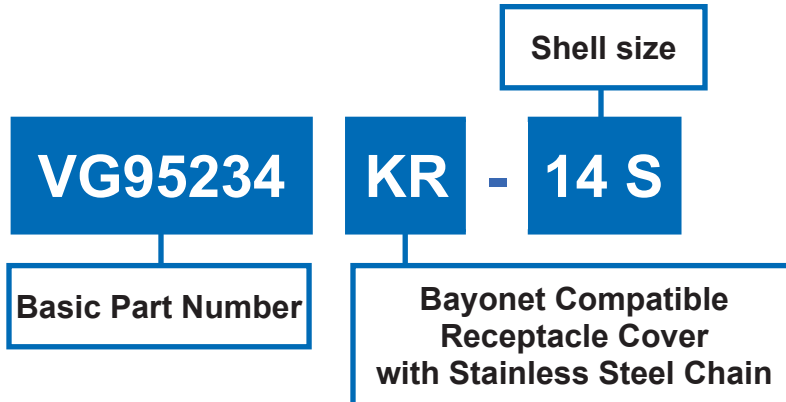

DIMENSIONS					
Connector Size	D1 Max	D2 +0.6 -0	L1 Min	L2 Max	Weight gr. Max
10 SL	23.5	4.3	90	15.5	16
14 S	30.5	4.3	90	15.5	18
16 S	33.0	4.3	90	15.5	19
16	33.0	4.3	100	21.2	23
18	37.5	4.3	100	21.2	27
20	41.0	4.7	115	21.2	30
22	44.0	4.7	115	21.2	33
24	47.5	4.7	115	21.2	37
28	54.5	4.7	160	21.2	42
32	61.0	5.5	160	21.2	48
36	67.5	5.5	160	21.2	55

**APPLICATION NOTES**

1. Metal protective cover for bayonet receptacle connectors with stainless steel chain.
2. Standard materials configuration consists of aluminum alloy with cadmium olive drab passivation IAW QQ-P-416.
3. Other types of front and rear connector accessories are available. See our website and/or contact the factory for complete information.