
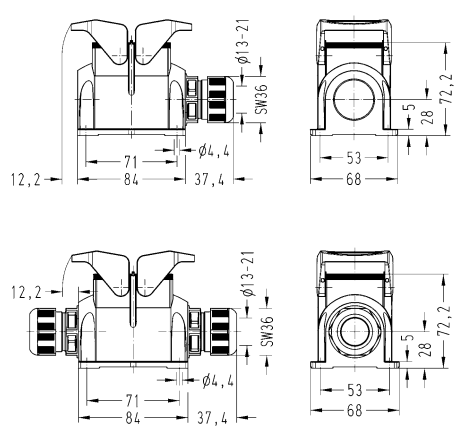

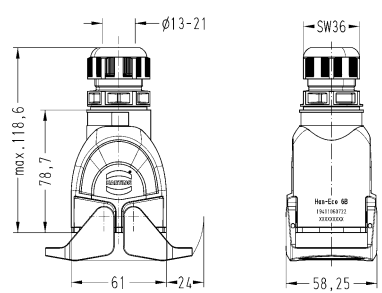


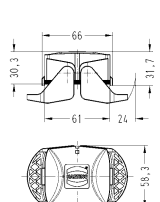

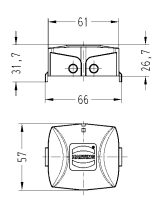



| Identification   | Cable entry              | Part number                              | Drawing<br>(dimensions in mm)  |
|--|--------------------------|--|--|
| <p>Han-Eco® ,<br/>Surface mounted housing,<br/>With integrated cable gland,<br/>Side entry</p>  | <p>1x M32<br/>2x M32</p> | <p>19 41 106 0232<br/>19 41 106 0272</p> |    |
| <p>Han-Eco® ,<br/>Cable to cable housing,<br/>With integrated cable gland,<br/>Top entry</p>   | <p>1x M32</p>            | <p>19 41 106 0722</p>                    |   |
| <p>Han-Eco® ,<br/>Protection cover for hoods</p>    |                          | <p>19 41 006 5406</p>                    |  |
| <p>Han-Eco® ,<br/>Protection cover for hoods,<br/>With fixing cord</p>                        |                          | <p>19 41 006 5407</p>                    |  |
| <p>Han-Eco® ,<br/>Protection cover for all housings,<br/>With fixing cord</p>                 |                          | <p>19 41 006 5404</p>                    |  |
| <p>Han-Eco® ,<br/>Protection cover for all housings</p>                                       |                          | <p>19 41 006 5405</p>                    |  |