



## Technical data

### NA2202LL/3AS

Roller follower with inner ring

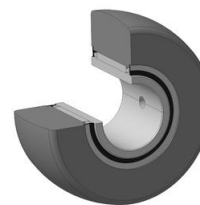

#### VISUAL (S)

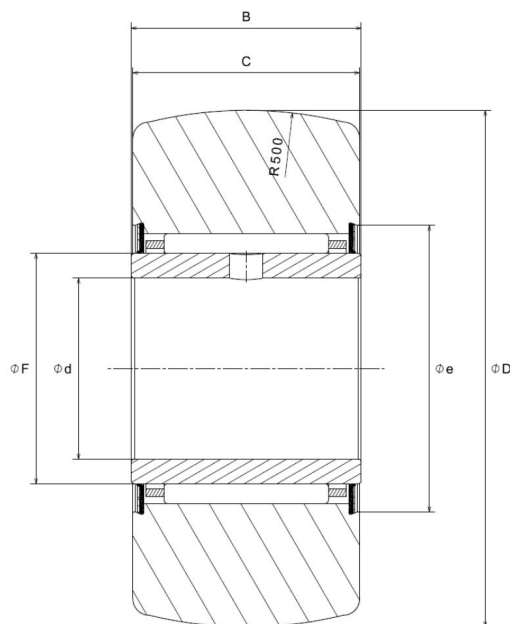

#### PRODUCT DEFINITION

|                                                      |         |
|------------------------------------------------------|---------|
| <b>Brand</b>                                         | NTN     |
| <b>d - Internal diameter</b>                         | 15 mm   |
| <b>D - External diameter</b>                         | 35 mm   |
| <b>C - Width of bearing, drawn cup or outer ring</b> | 13,8 mm |
| <b>F - Under roller diameter</b>                     | 20 mm   |
| <b>B - Bearing/Inner ring width</b>                  | 14 mm   |
| <b>e - Inlet diameter of roller or washer</b>        | 26 mm   |
| <b>R - Track roller radius</b>                       | 500 mm  |
| <b>rs - Min fillet radius</b>                        | 0,3 mm  |



#### NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00  
 S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072  
 SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

## PRODUCT DEFINITION

|                                  |          |
|----------------------------------|----------|
| <b>Bearing with/without cage</b> | Avec     |
| <b>Radial clearance class</b>    | CN       |
| <b>Precision class</b>           | P0       |
| <b>Mass</b>                      | 0,075 kg |

## PRODUCT PERFORMANCE

|                                                 |             |
|-------------------------------------------------|-------------|
| <b>Cr - Dynamic load rating</b>                 | 9,85 kN     |
| <b>C0r - Static load rating</b>                 | 14,1 kN     |
| <b>Track load capacity spherical outer ring</b> | 3,2 kN      |
| <b>N lim - Grease lubrication limit speed</b>   | 7500 tr/min |
| <b>Tmin - Min operating temperature</b>         | -20 °C      |
| <b>Tmax - Max operating temperature</b>         | 100 °C      |

## ESHOPDONOTDISPLAY

|                                 |                                    |
|---------------------------------|------------------------------------|
| <b>Tracepart</b>                | Oui/Yes                            |
| <b>Reference</b>                | NA2202LL/3AS                       |
| <b>Image</b>                    | NRBNA22_LL_1.jpg, NRBNA22_LL_3.jpg |
| <b>Rolling element material</b> | Acier 100Cr6                       |

