


Technical data

NUTR307/3AS

Roller follower with inner ring

Needle roller bearing, roller follower, full-complement cylindrical roller, with inner ring, double-side shields, spherical outer ring

VISUAL (S)

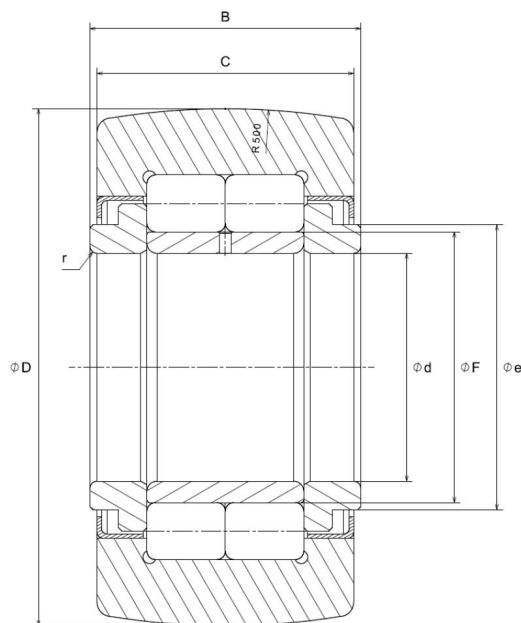

PRODUCT DEFINITION	
Brand	NTN
d - Internal diameter	35 mm
D - External diameter	80 mm
C - Width of bearing, drawn cup or outer ring	28 mm
F - Under roller diameter	41,5 mm
B - Bearing/Inner ring width	29 mm
e - Inlet diameter of roller or washer	44 mm
R - Track roller radius	500 mm

PRODUCT DEFINITION	
rs - Min fillet radius	0,6 mm
Bearing with/without cage	Sans
Radial clearance class	CN
Precision class	P0
Mass	0,84 kg

PRODUCT PERFORMANCE	
Cr - Dynamic load rating	62 kN
C0r - Static load rating	85,5 kN
Track load capacity spherical outer ring	9,8 kN
N lim - Grease lubrication limit speed	2400 tr/min
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	120 °C

ESHOPDONOTDISPLAY	
Tracepart	Oui/Yes
Reference	NUTR307/3AS
Image	NRBNUTR_1.jpg, NRBNUTR_3.jpg
Rolling element material	Acier 100Cr6

