



SIVACON, side panel / rear panel, Closed, IP55, H: 1800 mm, W: 1000 mm, RAL 7035

Model		
product brand name	SIVACON	
product designation	Side panel/rear panel	
design of the product	Closed	
design of the surface	Powder-coated	
design of the product EMC version	No	
Protection class		
protection class IP	IP55	
Appearance		
RAL color number	RAL 7035	
color	light grey	
Product details		
product component		
• cable entry	No	
• lock	No	
Mechanical Design		
height	1 800 mm	
width	1 000 mm	
depth	1 000 mm	
material	steel	
Approvals Certificates		
General Product Approval		Test Certificates
		other



[Special Test Certificate](#)

[Confirmation](#)

[Miscellaneous](#)

other

Environment

[Miscellaneous](#)

Siemens
EcoTech



[Environmental Confirmations](#)

Further information


Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1800-2UW61-1C>
Service&Support (Manuals, Certificates, Characteristics, FAQs,...)
<https://support.industry.siemens.com/cs/ww/en/ps/8MF1800-2UW61-1C>
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)
http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1800-2UW61-1C
CAx-Online-Generator
<http://www.siemens.com/cax>
Tender specifications
<http://www.siemens.com/specifications>

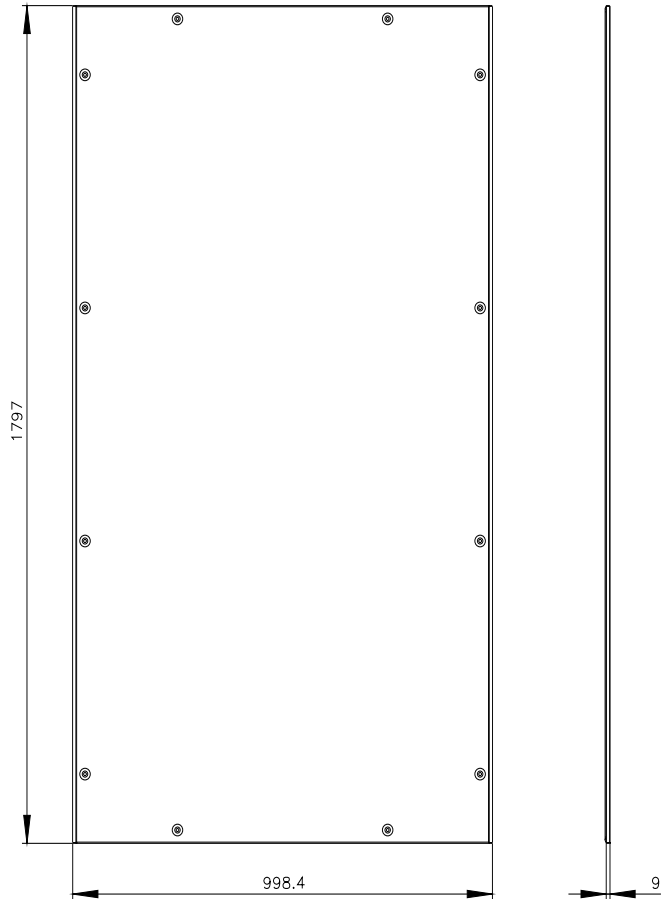

last modified: 5/24/2025 

