

Data sheet

3NW6603-4



Figure similar

SETRON, cylindrical fuse link, 10x85 mm, 10 A, gPV, Un DC: 1500 V

Model		
product brand name		SETRON
product designation		Cylindrical fuse link
General technical data		
operating class of the fuse link		gPV
type of voltage of the operating voltage		DC
supply voltage at DC		1 500 V
Main circuit		
operational current rated value		10 A
Product details		
product component striker		No
Mechanical Design		
mounting position		Any, preferably vertical
net weight		15 g
Approvals Certificates		
General Product Approval	other	Environment



Confirmation

Environmental Con- firmations

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3NW6603-4>

[Service&Support \(Manuals, Certificates, Characteristics, FAQs,...\)](#)

<https://support.industry.siemens.com/cs/ww/en/ps/3NW6603-4>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mfb=3NW6603-4

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

Tender specifications
<http://www.siemens.com/specifications>

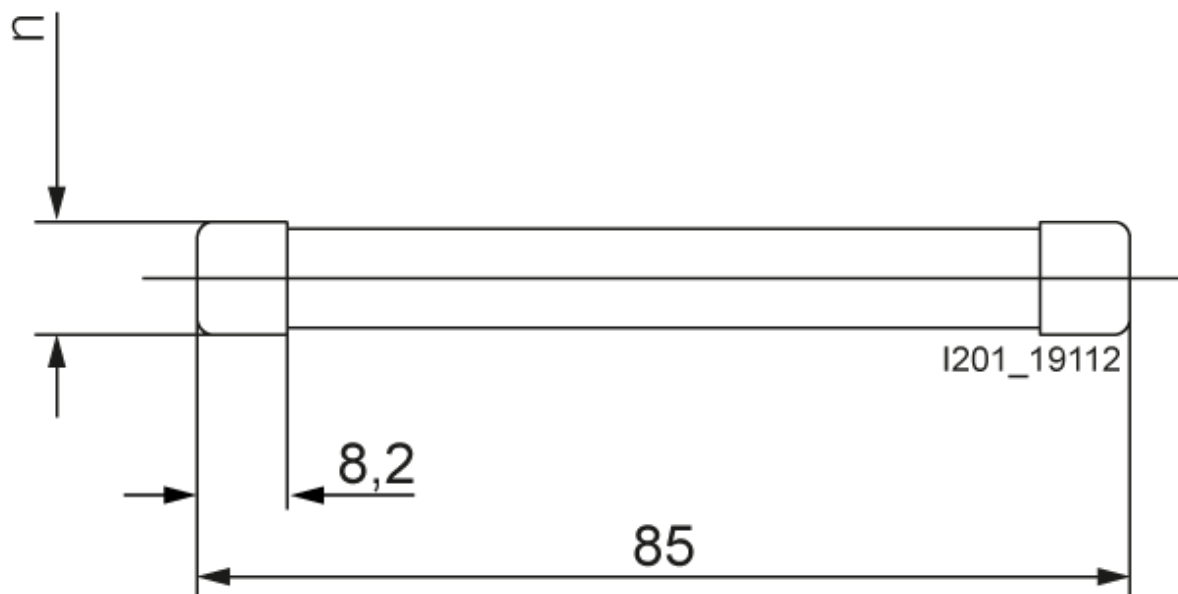

last modified:

4/11/2025 

