

Datasheet

Sealed Miniature Toggle Switch


RS Stock number 734-7019



Specifications:

MECHANICAL LIFE:	20,000 make-and-break cycles.
CONTACT RESISTANCE:	10mΩ max.
INSULATION RESISTANCE:	500V 500MΩmin.
DIELECTRIC STRENGTH:	1,000Vrms min. @ sea level.
WATER RESISTANCE:	100 make-and-break cycles min. at 10cm depth
OPERATING TEMPERATURE:	-30°C to 85°C.
CASE:	Dially phthalate (DAP) UL94v-0)
ACTUATOR:	Brass, chrome plated
Bushing:	Brass, nickel plated
Housing:	Stainless steel
CONTACT/TERMINAL:	Silver or gold plated
Switch Support:	Brass, tin plated
RoHS:	2002/95/EC

**Dimensions – inch
mm**

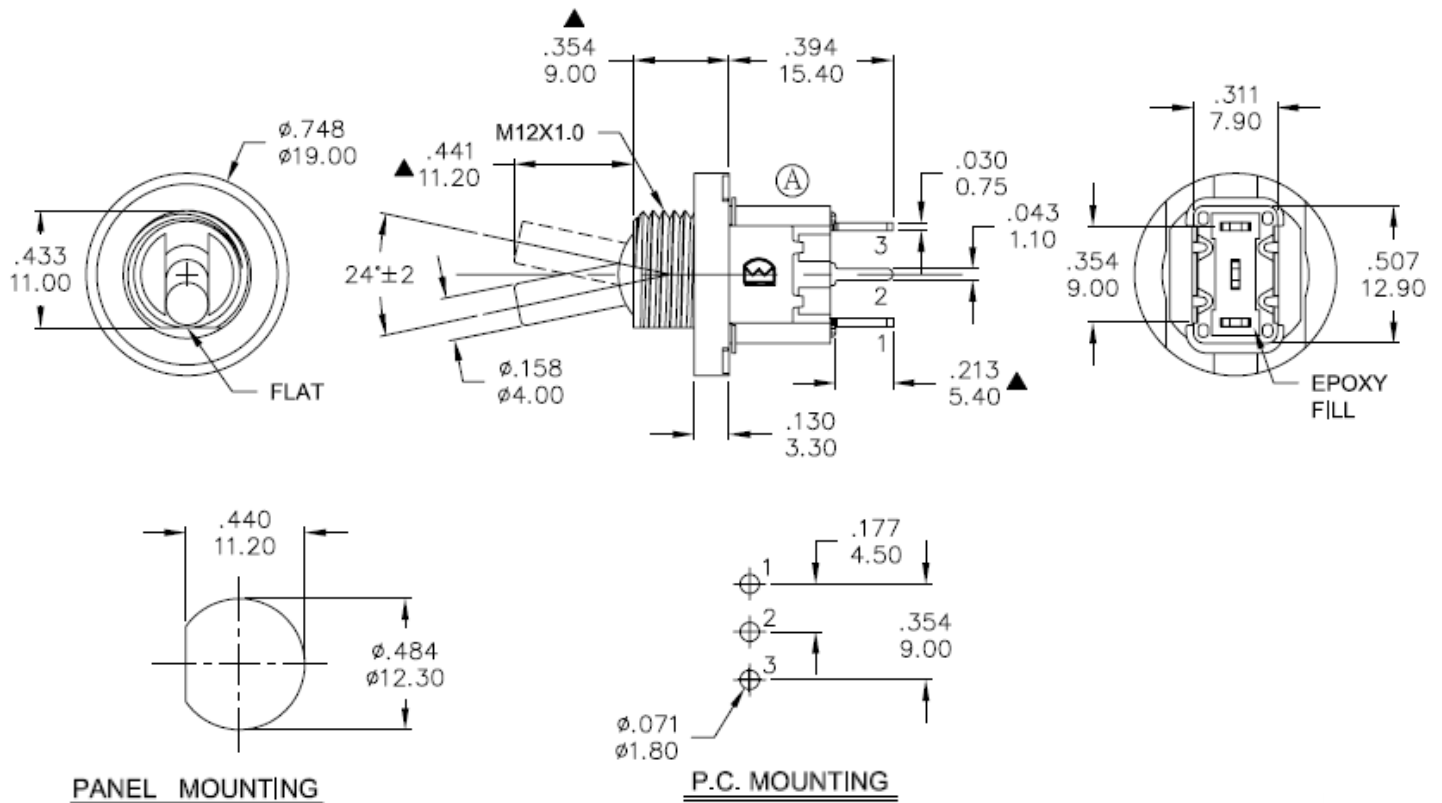

Model No.	POS.1	POS.2	POS.3
1FS4	MOM	OFF	MOM
Term. Comm.	2-3	OPEN	2-1
SCHEMATIC			

SWITCH FUNCTION