


1264 Screwdrivers for headless slotted screws



Features:

- The blade is made from special steel with a high silicon, chromium and vanadium content, to ensure improved performance in terms of torsional and flexural strength. A non-glare, matt chrome-plated finish has been chosen.
- The geometry of the tip has been designed to ensure perfect coupling between the blade and the screw head. The phosphate-coated finish prevents the tip from getting oxidized, while maintaining precise profiles.
- The texture has been inspired by the treads of Racing tyres, developed to maximize grip on different grounds. Hence it ensures effective screwdriver hold under any working conditions, for enhanced precision and control when fitting the tip onto the screw.

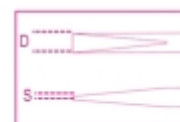

	art.	SxAxL mm	L1 mm	g
012640003	1264 2,5X60	0,5x2,5x60	160	33,2
012640006	1264 3X75	0,6x3x75	175	35,4
012640009	1264 3X100	0,6x3x100	200	36,6
012640012	1264 4X100	0,8x4x100	208	60,6
012640015	1264 4X125	0,8x4x125	233	63,0
012640018	1264 5X125	1x5x125	233	72,6
012640021	1264 5X150	1x5x150	258	76,8
012640024	1264 6,5X150	1,2x6,5x150	269	117,6