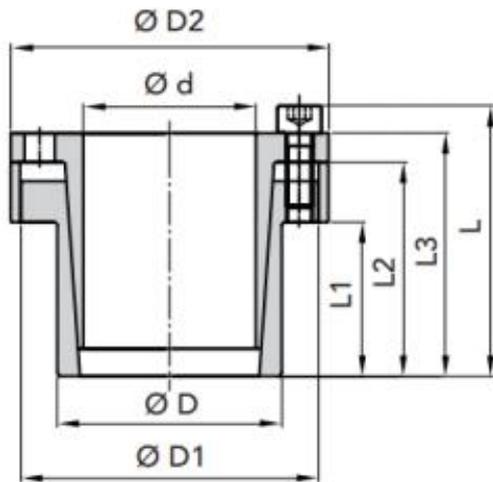


06800025

RCK 80 - Self centring

2D Technical Drawing

Dynamic 3D View
Technical Specifications

Part number (CODE)	06800025
Ød (DD) mm	25
ØD (D) mm	34
D1 (D1) mm	50
D2 (D2) mm	56
L1 (L1) mm	26
L2 (L2) mm	39.5
L3 (L3) mm	46.5
L (L) mm	52.5
Maximum torque Mt (MT) Nm	410
Clamping pressure - Shaft (CPS) N/mm ²	140
Clamping pressure - Hub (CPH) N/mm ²	102
Clamping screws DIN 912 MAT. 12.9 - Num. (CSN)	6
Clamping screws DIN 912 MAT. 12.9 - Type (CST)	M6x18
Clamping screws DIN 912 MAT. 12.9 - Torque (CSTQ) Nm	17.0