
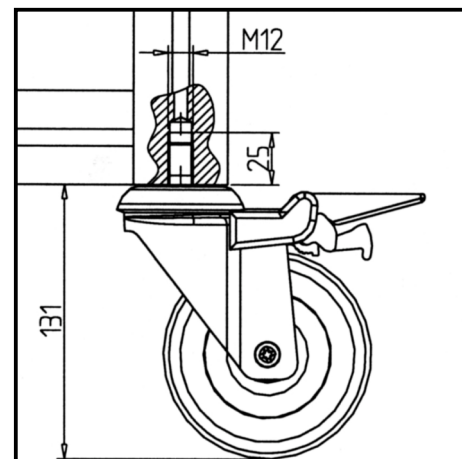
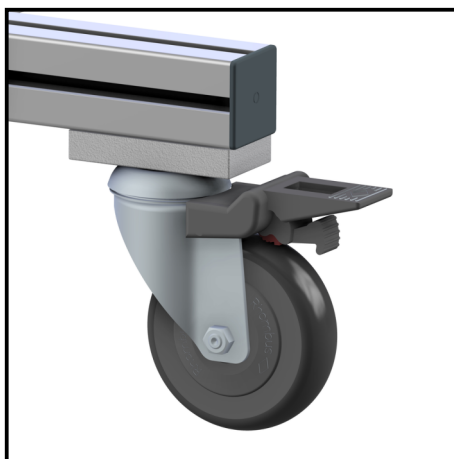


SWIVEL CASTOR WITH BRAKE D 100 X 131

Article Nr. 21.0031/0

[See the product on the website →](#)

[Download CAD Files →](#)

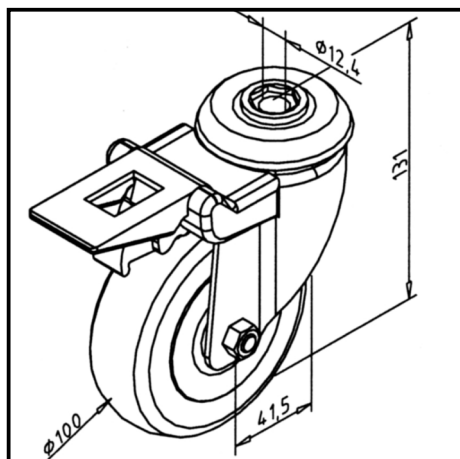

TECHN. DATA / ITEMS SUPPLIED

- Steel, galvanized
- Tire, rubber, grey
- With fastening material steel, zinc plated
- Load capacity 100 kg
- **Other versions upon request**
- Weight = 0.743 kg/piece

APPLICATIONS

- Movable tables
- Work stands
- Display windows, showcases

ASSEMBLY

- Connect directly to the central bore of the vertical profile with supplied hardware, drill and introduce thread M12
- If the roller is to be centrally positioned for profile cross sections of 45 x 90 or 90 x 90, a connection plate is required