

Rittal – The System.

Faster – better – everywhere.

► Second pair of mounting angles for Data Rack – DK 7296.000

Date : Apr 26, 2021

ENCLOSURES

POWER DISTRIBUTION

CLIMATE CONTROL

IT INFRASTRUCTURE


SOFTWARE & SERVICES

FRIEDHELM LOH GROUP



Second pair of mounting angles for Data Rack – DK 7296.000

created: 26.04.2021 build on www.rittal.com/uk-en

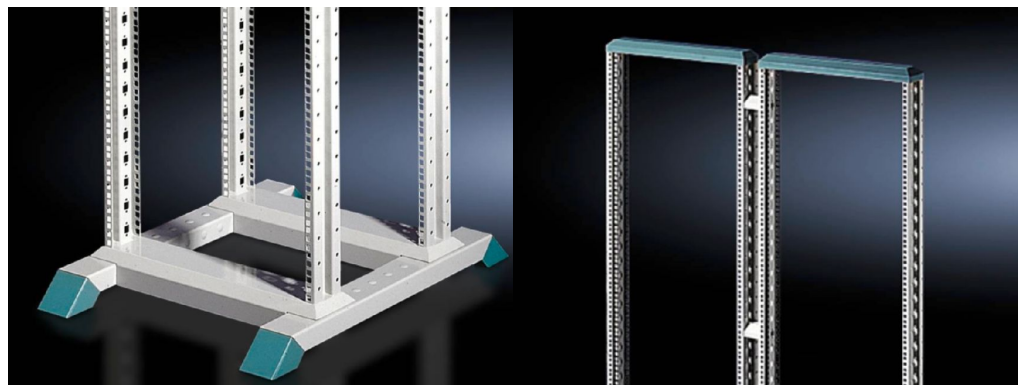

Product description

Description:	To accommodate 482.6 mm (19") network components or for the attachment of component shelves and slide rails. 482.6 mm (19") punched profile at the front, hole centre distance 465 mm (470 mm at the rear), tailored to the attachment of patch panels and cable routing rails. The mounting level may be positioned on a 50 mm pitch pattern. Minimum distance between levels 150 mm, maximum distance between levels 350 mm.
Material:	Sheet steel, 2 mm
Surface finish:	Spray-finished
Colour:	Profile frame: RAL 7035 Trim panel: RAL 5018
Supply includes:	Torsionally stiff profile frame with 482.6 mm (19") punchings Mounting accessories

Product description

Units:	31 U
Installation dimensions:	Installation width: 482,6 mm / 19"
Packs of:	1 pc(s).
Weight/pack:	11.68 kg
Copper weight (kg)	0

per piece):

EAN:	4028177128798
Customs tariff number:	94039010
ETIM 7.0:	EC002620
ETIM 6.0:	EC002620
eCl@ss 8.0/8.1:	27189261
eCl@ss 6.0/6.1:	27182590
Product description:	DK Second pair of mounting angles, 31 U, 482.6 mm (19"), For Data Rack
Approvals	
Certificates:	NA