




Datasheet

ENGLISH

Yoko Type Track Rollers

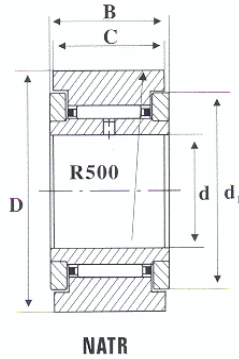

Bore Size (mm)	Roller Diameter (mm)	Length (mm)	Maximum Load-Dynamic (N)	Maximum Load-Static (N)	Maximum Speed-Grease (rpm)	Maximum Speed-Oil (rpm)	Stock No.
5	16	12	3700	3800	15400	22,000	471364
6	19	12	4250	4600	14000	20,000	471281
8	24	15	6800	7700	10500	15,000	471297
10	30	15	8100	9700	7700	11,000	471291
12	32	15	8700	11000	6300	9,000	471308
15	35	19	12900	19000	4900	7,000	471326
17	40	21	14200	20400	4200	6,000	471336
20	47	25	19500	32000	3430	4,900	471332
25	52	25	21200	38000	2520	3,600	471342

RS article no.	Boundary Dimensions (mm)				
	d	D	B	C	d1
471364	5	16	12	11	12
471281	6	19	12	11	14
471297	8	24	15	14	19
471291	10	30	15	14	23
471308	12	32	15	14	25
471326	15	35	19	18	27
471336	17	40	21	20	32
471332	20	47	25	24	37
471342	25	52	25	24	42