



10219012

3/4in x 7/16in - Chain sprockets ISO

2D Technical Drawing

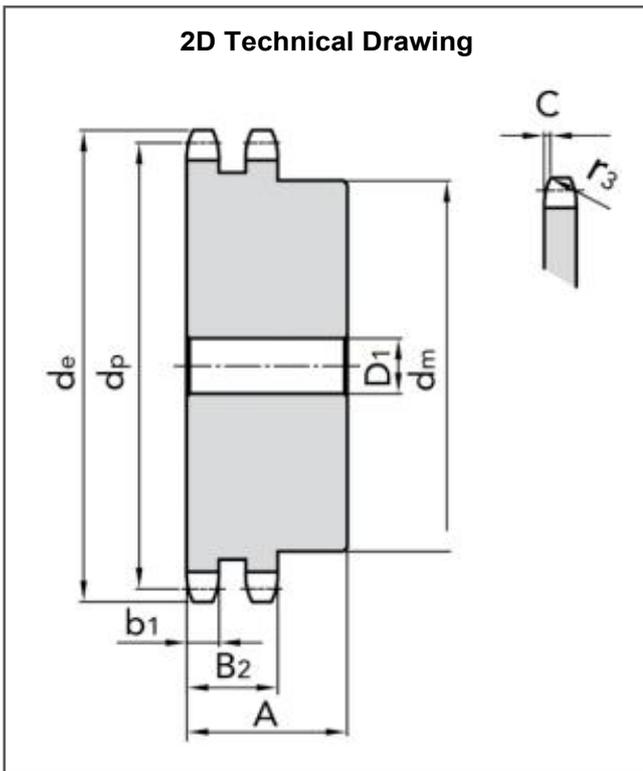

 Dynamic 3D View



### Technical Specifications

Number of teeth (T)	12
de (DE) mm	81.13
dp (DP) mm	73.60
Part number (CODE)	10219012
dm (DM) mm	53
D1 (D1) mm	16
A (A) mm	50
Tooth radius r3 (R3) mm	19
Radius width C (C) mm	2
Sprockets tooth width b1 (B1) mm	10.8
Sprockets tooth width B2 (B2) mm	30.3
Weight (WEIGHT) kg	1.02
Material (MAT)	STEEL C 45