 



silencer U-3/8-B

Part number: 6843

★ Core product range

FESTO

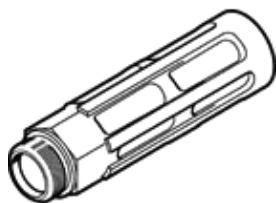

Data sheet

Feature	Value
Assembly position	Any
Operating pressure complete temperature range	0 ... 10 bar
Flow rate to atmosphere	5,800 l/min
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Sound pressure level	80 dB(A)
Ambient temperature	-10 ... 70 °C
Product weight	37 g
Pneumatic connection	G3/8
Material of silencer insert	PE
Material of threaded plug	Aluminium
Materials note	Free of copper and PTFE Conforms to RoHS
Material housing	Aluminium