


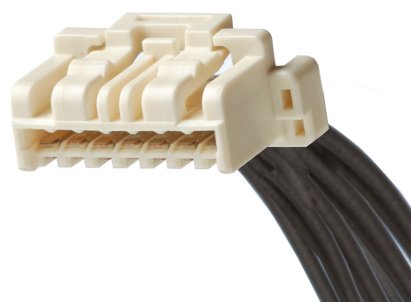

**Part Number :** 151350706  
**Product Description :** CLIK-Mate-to-CLIK-Mate  
Off-the-Shelf (OTS) Cable Assembly, 1.50mm  
Pitch, Single Row, 600.00mm Length, 7  
Circuits, Beige  
**Series Number :** 15135  
**Status :** Active  
**Product Category :** Power and Signal Cable  
Assemblies



Documents & Resources

Drawings  
[151350706\\_sd.pdf](#)

Product Environment Compliance

Compliance

|                    |                                                                                       |
|--------------------|---------------------------------------------------------------------------------------|
| GADSL/IMDS         | Not Relevant                                                                          |
| China RoHS         |  |
| EU ELV             | Not Relevant                                                                          |
| Low-Halogen Status | Not Low-Halogen per IEC 61249-2-21                                                    |
| REACH SVHC         | Not Contained per D(2024)6225-DC (07 Nov 2024)                                        |
| EU RoHS            | Compliant per EU 2015/863                                                             |

Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

EU RoHS Certificate of Compliance

---

## Part Details

### General

|                        |                                                                                                                         |
|------------------------|-------------------------------------------------------------------------------------------------------------------------|
| Status                 | Active                                                                                                                  |
| Category               | Power and Signal Cable Assemblies                                                                                       |
| Series                 | 15135                                                                                                                   |
| Description            | CLIK-Mate-to-CLIK-Mate Off-the-Shelf (OTS) Cable Assembly, 1.50mm Pitch, Single Row, 600.00mm Length, 7 Circuits, Beige |
| Application            | Signal, Wire-to-Board                                                                                                   |
| Assembly Configuration | Dual Ended Connectors                                                                                                   |
| Connector to Connector | CLIK-Mate-to-CLIK-Mate                                                                                                  |
| Product Name           | CLIK-Mate                                                                                                               |
| Type                   | Discrete Wire Assembly                                                                                                  |
| UPC                    | 191128160414                                                                                                            |

### Electrical

|                               |                  |
|-------------------------------|------------------|
| Current - Maximum per Contact | 2.0A             |
| Voltage - Maximum             | 100V AC (RMS)/DC |

### Physical

|                                |              |
|--------------------------------|--------------|
| Cable Length                   | 600.00mm     |
| Circuits (Loaded)              | 7            |
| Circuits (maximum)             | 7            |
| Color - Resin                  | Beige        |
| Gender                         | Male-Male    |
| Lock to Mating Part            | Yes          |
| Material - Metal               | Copper Alloy |
| Material - Plating Mating      | Tin          |
| Material - Plating Termination | Tin          |
| Material - Resin               | PBT          |
| Net Weight                     | 13.916/g     |
| Number of Rows                 | 1            |
| Overmolded                     | No           |
| Packaging Type                 | Bag          |

|                             |                      |
|-----------------------------|----------------------|
| Pitch - Mating Interface    | 1.50mm               |
| Plating min - Mating        | 0.406µm              |
| Plating min - Termination   | 0.406µm              |
| Single Ended                | No                   |
| Termination Interface Style | Crimp or Compression |
| Wire/Cable Type             | UL 1061              |
| Wire Size (AWG)             | 24                   |

---

## Mates With / Use With

### Mates with Part(s)

| Description                                                    | Part Number   |
|----------------------------------------------------------------|---------------|
| 1.50mm Pitch CLIK-Mate Bottom Entry Single Row PCB Receptacles | <u>503395</u> |
| 1.50mm Pitch CLIK-Mate Right-Angle Single Row PCB Receptacles  | <u>503175</u> |
| 1.50mm Pitch CLIK-Mate Right-Angle Single Row PCB Receptacles  | <u>502585</u> |
| 1.50mm Pitch CLIK-Mate Vertical Single Row PCB Receptacles     | <u>503159</u> |
| 1.50mm Pitch CLIK-Mate Vertical Single Row PCB Receptacles     | <u>502584</u> |