

## SVS ECO LED VALVE PLUG FORM C 8MM LED VDR 24V

2+PE field-wireable M12

Form C (8 mm)

24 V AC/DC  $\pm 15\%$

LED and VDR



metric

Field wireable (screw terminals)


Plastic housings with good resistance against chemicals and oils. The resistance to aggressive media should be individually tested for your application. Further details on request.

### [Link to Product](#)

Illustration

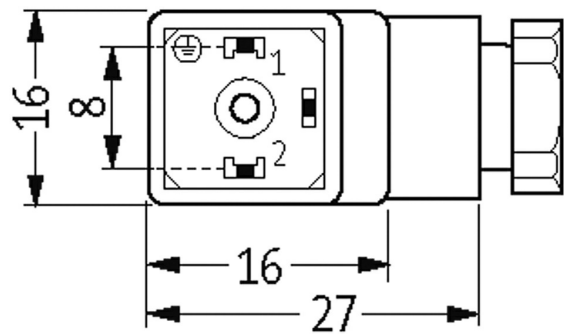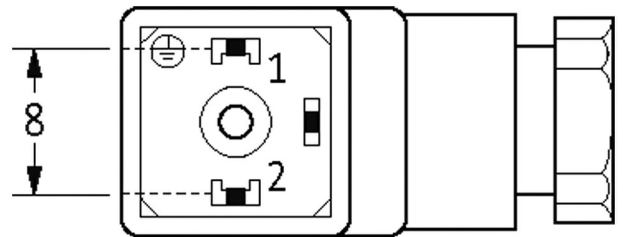

Height: 26 mm

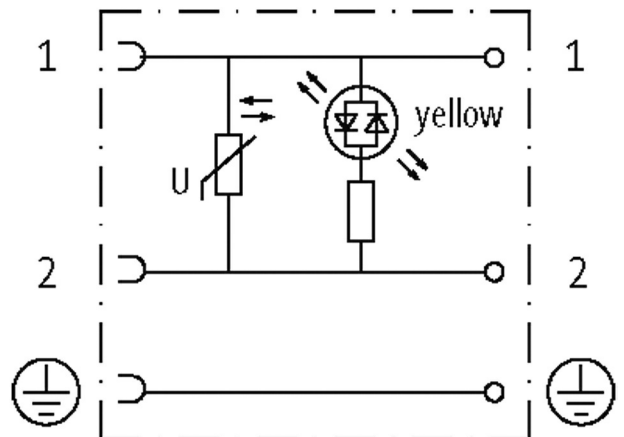

Product may differ from Image

**Approvals**

EAC

ChinaRoHS25

**Form**

Form 30105

**Technical Data**

Operating voltage	24 V AC/DC $\pm 15\%$
Operating current per contact	max. 1.5 A
Configuration	2 contacts + PE
Connection cross section	max. 0.5 mm <sup>2</sup>
Sealing range (cable $\varnothing$ )	4...6 mm
LED display	yellow
Locking of ports	M2.5 (recommended torque 0.4 Nm)
Compression gland	M12×1.5 mm
Contact figure	Cable outlet can be turned in 90° steps
Protection	IP65 inserted and tightened (EN 60529)
Additional suppressor	VDR

**General data**

Temperature range	-40...+90 °C
Material (gasket)	NBR
Mounting method	inserted, tightened

**Commercial data**

country of origin	HU
customs tariff number	85366990
EAN	4048879187008
eClass	27279221
Packaging unit	1