


## KB515 EQ USB-C/USB-A Wired Keyboard

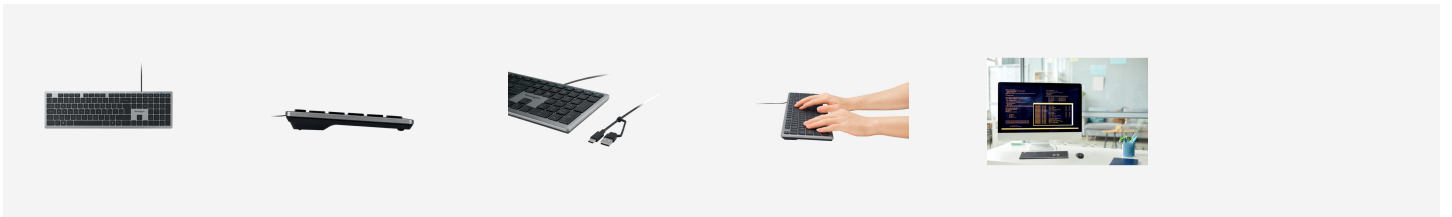

Designed for professionals seeking a keyboard that enhances efficiency and comfort, the KB515 EQ USB-C/USB-A Wired Keyboard features a full-size ISO layout with 16 programmable keys and an integrated AI Copilot key\* to support productivity and custom workflows. The responsive scissor-switch keys deliver a quiet typing experience, while LED indicators for Num Lock, Caps Lock and Scroll Lock keep you informed. The outer case of this keyboard is made with 43% post-consumer recycled (PCR) content\*\* and it is shipped in FSC® certified packaging. A durable 1.5m (5') USB-C® cable with tethered USB-A adapter delivers a reliable wired performance while easily accommodating different setups. Windows, macOS and ChromeOS compatible, it includes a 3-year limited warranty. \* Windows only. \*\* Excluding PCB board and dongle.



## Attributes

- 16 programmable keys, a dedicated AI Copilot key\* and Function Lock for seamless multitasking. \* Windows only.
- Features a 1.5m (5') wired USB-C® connection with tethered USB-A adapter that ensures zero lag.
- Full-size ISO layout with 110 keys includes a number pad for efficient data entry and function keys to support multitasking.
- Scissor-switch keys provide a quiet and responsive feel, help reduce fatigue and support accurate typing.
- Status lights for Num Lock, Caps Lock and Scroll Lock provide instant visibility into your current settings.
- The plastic used in the outer case of this keyboard is made with 43% post-consumer recycled (PCR) content\* and it is shipped in FSC® certified packaging. \* Excludes PCB board and dongle.
- Connects effortlessly without software or drivers.
- 3-year limited warranty.

## Specifications

Number	K75410UK
Colour	-----
Dimensions (W x H x D)	125 x 20 x 431 mm
Weight	600 g
Pallet quantity	260
EAN code	5028252658942