


28 PUV

4-way wheel wrench

passenger cars

Code	ETIM
6228260	EC003993
EAN	UNSPSC
4010886622827	27-11-17-14
Country of origin	eCl@ss
Germany	21-04-01-90
Customs tariff number	
82041100	

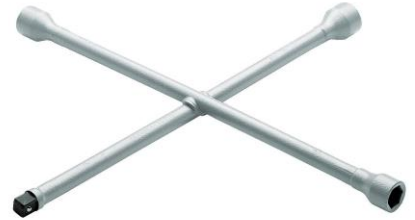

Article description

- Acc. to DIN 3119, ISO 6788
- For car wheel nuts in metric and inch sizes
- Vanadium steel 31CrV3
- Grey powder-coated
- With protective central reinforcement (DBGM = German utility patent)
- Hot forged hexagon
- The collar, typical of GEDORE 4-way wheel wrenches, enlarges the welding area
- The positive-fit joint remains solid even under extreme loading
- Dimensions: 420 x 420 mm

Article parts list

17x19 (3/4")x21x1/2" square

Article information

Contents (Qty of pieces)	1	Insert-Ø 1	26,0 mm
Net weight [kg]	1,3 kg	Insert-Ø 2	28,5 mm
Total length [mm]	320 mm	Width across flats [mm]	17 x 19 x 21
Total width [mm]	320 mm	Width across flats 2 [mm]	19
Total height [mm]	32 mm	Width Across Flat 3 [mm]	21
Surface	grey powder-coated	Insert-Ø 3	30,5 mm
Use	For car wheel nuts in metric and inch sizes	Insert-Ø 4	17,5 mm
Material	31CrV3	Insert-Ø	26,0 mm x 28,5 mm x 30,5 mm x 17,5 mm
Drive connector square (male)	1/2"	Width across flats 2 [AF]	3/4"
Width across flats 1 [mm]	17		