


# vacuum filter

## VAF-DB-3/8

Part number: 553140

FESTO

for filtering dirt particles

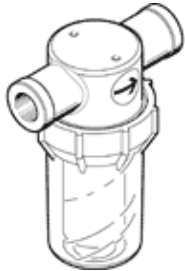

### Data sheet

Feature	Value
Assembly position	Vertical
Grade of filtration	80 µm
Operating pressure	-0.95 ... 0 bar
Note on operating pressure	Only for application in open vacuum systems
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7:-:-]
Ambient temperature	-5 ... 50 °C
Max. tightening torque	15.3 Nm
Product weight	156 g
Mounting type	Line installation with wall/surface fixing
Pneumatic connection	G3/8
Vacuum connection	G3/8
Materials note	Contains PWIS substances Conforms to RoHS
Material seals	NBR
Material filter	PE
Material housing	PP reinforced
Material bowl	PA
Ejector pulse suitability	≤ 7 bar